

DOC.TYPE: SPECIFICATION DATA SHEET GE2004-9392	SUBJECT: HALOGEN CAPSULE LAMP G9 240V 25W 1500HRS	DRAWING No.: GE2004-7507 FILE ID.: DATASHEETG9240 25CL.DOC
---	---	---


GENERAL INFORMATION		TECHNICAL DATA	
CODE:	SKU 10809	VOLTAGE	240V
		WATTAGE	25 W
CAP:	G9	RATED WATTAGE	25 W + 8%
BULB:	UV control		
APPLICATION	GENERAL LIGHTING	RATED LUMENS	260 lm –15%
BURNING POSITION	Universal		
PERMISSIBLE PINCH TEMPERATURE	Max.350°C	LIFETIME	1500 hours
PERMISSIBLE BULB TEMPERATURE	Min.250 °C / Max. 900°C	COLOR	2900K

DIMENSIONS (mm)

min. nom. max.

A 13.0

B 54.0

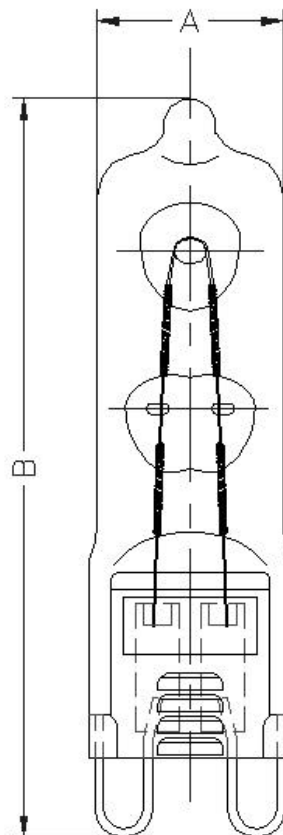

Relevant Standards: IEC 60432, IEC 60357, IEC 60061