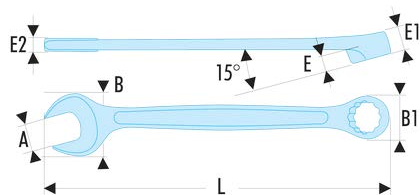
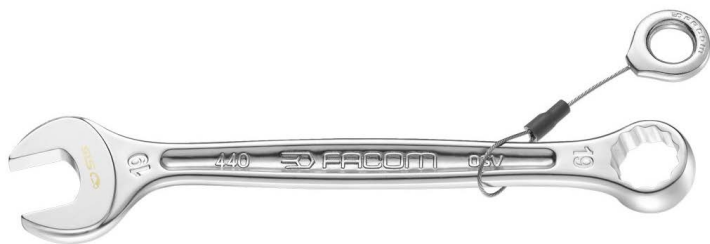


**440.22SLS 440.SLS - Metric combination wrenches****Description :**

- Tool equipped with a FACOM SLS attachment solution, preventing any risk of accidental falls.
- The crimped "sliding" cable solution, selected and tested by FACOM, maintains user ergonomics (8 - 30 mm wrenches).
- Standard wrench for all current applications.
- High mechanical strength combined with compact size meeting aeronautical standards.
- Ring head:
  - Ring open end (size E) designed for better access to series or embedded screws.
  - OGV® profile with 12-point ring for powerful tightening while protecting the nut.
  - Ring head angled at 15°.
- Open end head:
  - Open end angled at 15°.
  - Open end head-handle geometry optimised for increased access.
- Metric sizes: 6 to 34 mm.
- Presentation: satin chrome finish.

---

**A [mm]:** 22

---

**B [mm]:** 46,9

---

**B1 [mm]:** 32,3

---

**C1 [mm]:** 13,3

---

**E [mm]:** 8,3

---

**E1 [mm]:** 13,3

---

**E2 [mm]:** 9,0

---

**L [mm]:** 248

---

**[g]:** 255

---