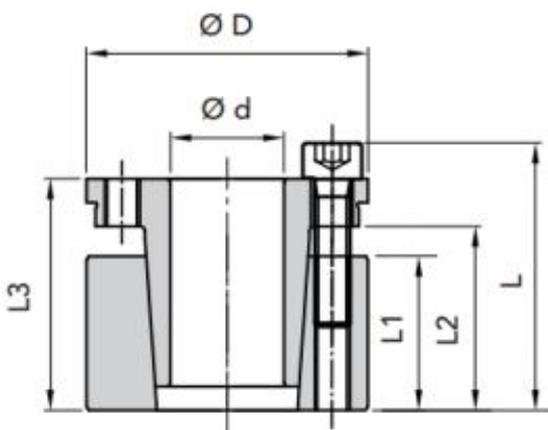


06700040

RCK 70 - Self centring

2D Technical Drawing

Dynamic 3D View
Technical Specifications

Part number (CODE)	06700040
Ød (DD) mm	40
ØD (D) mm	65
L1 (L1) mm	26
L2 (L2) mm	31
L3 (L3) mm	39
L (L) mm	45
Maximum torque Mt (MT) Nm	1350
Clamping pressure - Shaft (CPS) N/mm ²	200
Clamping pressure - Hub (CPH) N/mm ²	125
Clamping screws DIN 912 MAT. 12.9 - Num. (CSN)	8
Clamping screws DIN 912 MAT. 12.9 - Type (CST)	M6x25
Clamping screws DIN 912 MAT. 12.9 - Torque (CSTQ) Nm	17
Extraction thread - Type (ETT)	M6
Extraction thread - Num. (ETN)	4
Weight (WEIGHT) kg	0.60