

Features

- Crocodile Clips
- Automotive clip
- Jaw open 3/4" (19 mm) max
- Material: Copper
- Length: 3" (76.2 mm)
- Rating: 75 Amps

RS PRO Crocodile Clips,Copper Contact, 75A

RS Stock No.: 0205391



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Crocodile Clips



• It is suitable for applications that require strong hardwearing clips. The teeth mesh on three sides of the jaw ensures reliable contact with screw and crimp termination.

- Can be attached by crimp or screw connection
- Automotive test system
- Automotive analyser

General Specifications

Material	Copper
Product Name	Crocodile Clips
Type	Automotive Clip
Colour	Copper
Insulated	No
Connection Type	Can be attached by crimp or screw connection

Commented [波幸1]:

Commented [波幸2]:

Electrical Specifications

Current rating	75A
----------------	-----

Mechanical Specifications

Jaw Opening ($\pm 10\%$)	3/4" (19 mm) max
Contact Material	Copper
Insulation Material	No
Dimensions ($\pm 10\%$)	Overall length 3"(76.2mm), overall width 13/20"(16.5mm), overall height 15/16"(23.81mm)


Approvals

Crocodile Clips



Standards Met	RoHS Compliant
Declarations	Reach

Spec Drawings Diameter

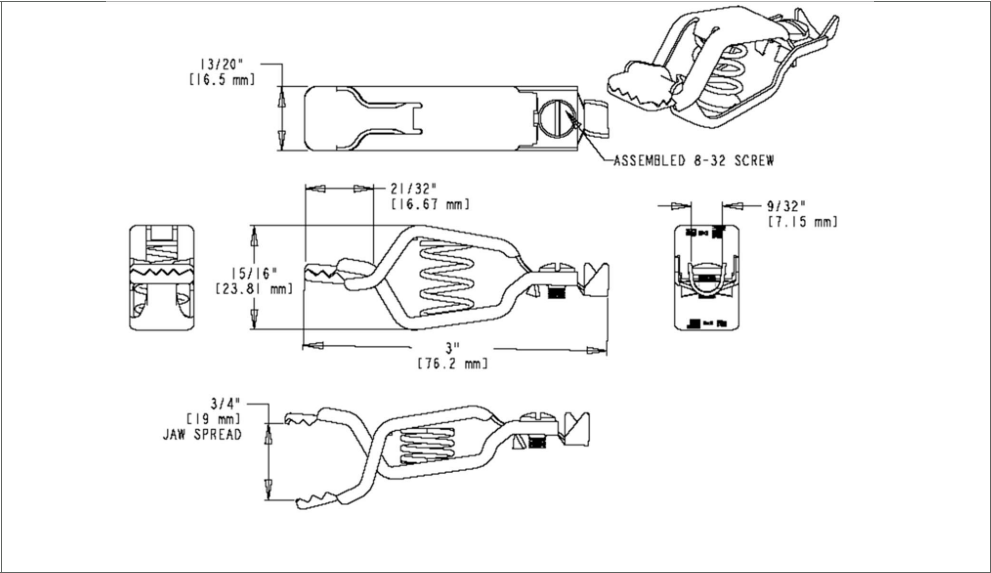

PRODUCT DIMENSION DRAWING AND ADDITIONAL INFORMATION