

HC-M-BS-M20 - Screw plug

1645846

<https://www.phoenixcontact.com/gb/products/1645846>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Screw plug, material for screw connection: Brass, nickel-plated, connecting thread: M20 x 1.5, color: silver-colored



Commercial data

| | |
|--------------------------------------|---------------------|
| Item number | 1645846 |
| Packing unit | 10 pc |
| Minimum order quantity | 10 pc |
| Sales key | AF7DZX |
| Product key | AF7DZX |
| Catalog page | Page 702 (C-2-2019) |
| GTIN | 4017918951092 |
| Weight per piece (including packing) | 11.3 g |
| Weight per piece (excluding packing) | 10.708 g |
| Customs tariff number | 74198090 |
| Country of origin | DE |

HC-M-BS-M20 - Screw plug

1645846

<https://www.phoenixcontact.com/gb/products/1645846>



Technical data

 
Product properties

| | |
|--------------|----------------------------|
| Product type | Plug for cable screw gland |
|--------------|----------------------------|

Connection data

| | |
|-------------------|------|
| Tightening torque | 5 Nm |
|-------------------|------|

Dimensions

| | |
|----------------------------------|--|
| Dimensional drawing |  |
| Length | 9 mm |
| Length of the connecting thread | 6 mm |
| Length without connecting thread | 3 mm |
| Diameter | 20 mm |
| Connecting thread diameter | 20 mm |
| Wrench size, union nut | 22 mm |
| Hexagon angular dimension | 24 mm |
| Thread type connection side | M20 x 1.5 |
| Thread pitch | 1.5 mm |

Material specifications

| | |
|-------------------------------|----------------------|
| Seal material O-ring | NBR |
| Housing surface material | Ni |
| Material for screw connection | Brass, nickel-plated |

Cable/line

| | |
|--------------|----|
| Halogen-free | no |
|--------------|----|

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|------------------|
| Degree of protection | IP68 |
| Ambient temperature (operation) | -20 °C ... 80 °C |

HC-M-BS-M20 - Screw plug


1645846

<https://www.phoenixcontact.com/gb/products/1645846>



Drawings

Dimensional drawing

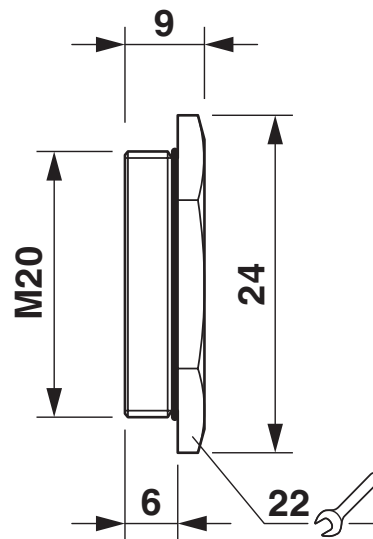

Dimensional drawing

HC-M-BS-M20 - Screw plug

1645846

<https://www.phoenixcontact.com/gb/products/1645846>



Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 23111190 |
|-------------|----------|

ETIM

| | |
|----------|----------|
| ETIM 9.0 | EC000032 |
|----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

HC-M-BS-M20 - Screw plug



1645846

<https://www.phoenixcontact.com/gb/products/1645846>

Environmental product compliance

EU RoHS

| | |
|---|------|
| Fulfills EU RoHS substance requirements | Yes |
| Exemption | 6(c) |

China RoHS

| | |
|--|---|
| Environment friendly use period (EFUP) | EFUP-50 |
| | An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required. |

EU REACH SVHC

| | |
|-------------------------------------|--------------------------------------|
| REACH candidate substance (CAS No.) | Lead(CAS: 7439-92-1) |
| SCIP | 3e3a4946-cc6a-49b3-ba17-ed88029a89a7 |

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd
Halesfield 13, Telford
Shropshire, TF7 4PG
01952 681700
info@phoenixcontact.co.uk