


NATR20-PP

Galet de roulement

Yoke type track rollers NATR...-PP-A, single row needle roller bearings with particularly thick-walled outer ring, needle roller and cage assembly and an inner ring, axial guidance of outer ring is provided by the plastic axial plain washers and contact washers, three-stage sealing by plastic axial plain washer on both sides

Information technique

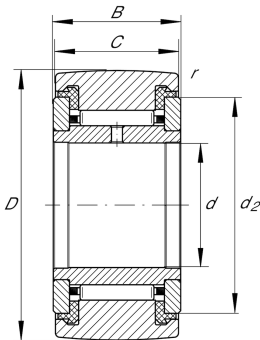

Votre alternative produit actuelle

joint	PP	Joint frottant des deux côtés
profile bague extérieure	IOP	Optimized INA-profile
dispositif de lubrification	IR	Via inner ring

dimensions principale & données de performance

d	20 mm	Alésage
D	47 mm	Diamètre extérieur
B	25 mm	Largeur, bague intérieure
C _{r w}	15.400 N	Charge dyn. de base, radiale
C _{0r w}	26.000 N	Charge stat. de base, radiale
C _{ur w}	3.450 N	Limite à la fatigue, radiale
n _{D G}	2.400 1/min	Vitesse pour une lubrification à la graisse
F _{0r per}	26.000 N	Charge radiale statique admissible
F _{r per}	26.000 N	Charge radial dynamique admissible sur bague extérieure
≈m	250 g	Poids

Dimensions

C	24 mm	Largeur, bague extérieure
d ₂	36,5 mm	Diamètre extérieur rondelle de butée
r _{min}	1 mm	Dimension minimum de chanfrein



Caractéristiques



Effort radial



Lubrification à vie, sans entretien



Lubrification à la graisse



Étanche des 2 côtés