


Strut profile 40x40L

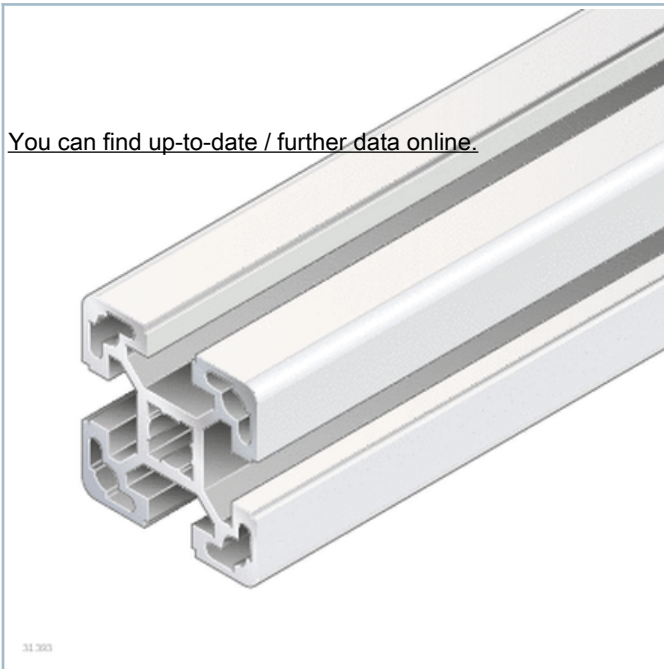

Product description

[Quick & Easy profile finishes](#)

[Introduction to strut profiles](#)

Technical data

[Quick & Easy profile finishes](#)

Dimensions

Strut profile 40x40L

40x40L

A = 5,6 cm²
 $I_x = 9,1 \text{ cm}^4$
 $I_y = 9,1 \text{ cm}^4$
 $W_x = 4,5 \text{ cm}^3$
 $W_y = 4,5 \text{ cm}^3$
 $I_t = 1,3 \text{ cm}^4$
 $W_t = 0,74 \text{ cm}^3$
m = 1,5 kg/m

19199

Ordering codes

The following caps with holes are needed:



40x40 signal gray (1 item)





40x40 black (1 item)

The following cover caps are needed:

40x40 signal gray (1 item)

40x40 black (1 item)

	L			ESD	No.
	mm				
Strut profile 40x40L	50 ... 6070		1		3842993120
Strut profile 40x40L M12/-	60 ... 6000		1		3842993121
Strut profile 40x40L M12/M12	110 ... 6000		1		3842993122
Strut profile 40x40L M12/D17	90 ... 6000		1		3842993123
Strut profile 40x40L D17/-	60 ... 6000		1		3842993124
Strut profile 40x40L D17/D17	80 ... 6000		1		3842993125
Strut profile 40x40L D17/D17V	80 ... 6000		1		3842993126
Strut profile 40x40L D9,8/D9,8	80 ... 6000		1		3842993129
Strut profile 40x40L, 20xL=6070mm	6070	20			3842529339
Strut profile 40x40L Q&E, L50-6000	50 ... 6070				3842993724
Cover cap 40x40, signal gray			100		3842548746

	L			ESD	No.
	mm				
Cover cap 40x40, black			20		3842548747
Cover cap with hole 40x40, signal gray			20		3842548782
Cover cap with hole 40x40, black			20		3842548783
Strut profile 40x40L	6070		1		3842529340

Quick & Easy profile finishes

Standard profile finishes (note minimum length) ¹⁾	M12 / D9,8 / D17 / DB17 / F1 (A)
Customized profile finishes ($L_{\max} = 5400$ mm) ²⁾	DI / DIS / MT / MTS / MI / MIS / DG

1) For the specified slots

2) $DG_{\max} = 45^\circ$; $L_{\min1} / L_{\min2} = 370 / 440$ mm