



**Part Number :** [192020031](#)


**Product Description :** NylaKrimp Butt Splice for 16-14 AWG Wire

**Series Number :** 19202

**Status :** Active

**Product Category :** Splices

**Engineering Number :** BS-N-331

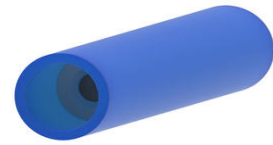

---

## Documents & Resources

### Drawings

[192020031\\_sd.pdf](#)

### 3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)


### Specifications

[PS-19902-013-001.pdf](#)

---

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	per SJ/T 11365-2006 
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

## Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## Substances of Interest

- PFAS

## EU RoHS Certificate of Compliance

## Additional Product Compliance Information

---

## Part Details

### General

Status	Active
Category	Splices
Series	19202
Description	NylaKrimp Butt Splice for 16-14 AWG Wire
Product Name	NylaKrimp
Style	Standard
Type	Butt Splice
UPC	800753047822

### Agency

CSA	LR18689
UL	E32244

### Electrical

Voltage - Maximum	600V
-------------------	------

### Physical

Barrel Type	Closed - Brazed
Color - Resin	Blue
Flammability	94V-2
Insulation	Nylon (PA)
Material - Metal	Copper

Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	1.343/g
Packaging Type	Bag
Temperature Range - Operating	-55° to +105°C
Wire Insulation Diameter	4.32mm max.
Wire Size (AWG)	14, 16
Wire Size mm <sup>2</sup>	1.30-2.00

---

## Application Tooling

### Global

Description	Part Number
PremiumGrade Hand Crimp Tool for Avikrimp and Insulkrimp Terminals and Splices, 22-10 AWG and 6.0-0.5mm <sup>2</sup> (Rings, Spades, Hooks, Block Spades and Flanged Spades)	<u>640010100</u>
PremiumGrade Hand Crimp Tool for Insulkrimp Terminals and Splices, 22-10 AWG (Rings, Spades, Hooks, Block Spades and Flanged Spades)	<u>640010300</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>640050100</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>640050300</u>
ServiceGrade Hand Crimp Tool for Field Repair only, for production use our PremiumGrade Tool	<u>640160036</u>