

NO MERCURY ADDED


- Description** : Mercury Free Alkaline Manganese Battery,
AA Size
- Chemical System** : Alkaline Manganese
- Nominal Voltage** : 1.5 Volts
- Nominal Dimensions** : Ø14.5 mm x 50.5 mm
- Terminals** : Protruded positive(+) and flat negative(-) contacts
- Jacket** : Foil jacket
- Applications** : All electronic devices, e.g. toys, digital camera, mobile phone, PDA, photographic equipment, data banks, calculators, audio appliances, remote controls, paging machines.
- Warranty Period** : 36 months
- Average Weight** : 24.5g

Cross References:



GP	JIS	IEC	Eveready	Duracell
15AU	LR6	LR6	E91	MX1500

Typical Service Life:

Discharge Resistance	Discharge Condition	End Point Voltage	Service Life
10 Ohms	24 Hrs/Day	0.9V	20.2Hrs

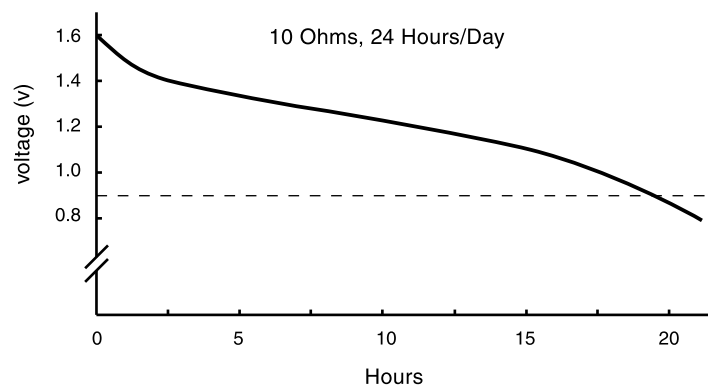

Model No.: **GP15AUP**

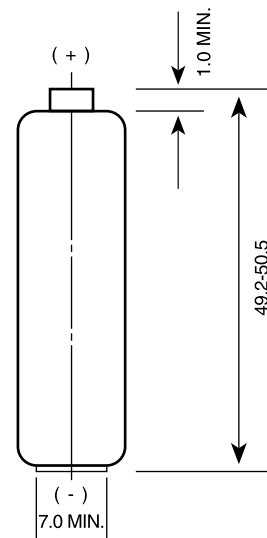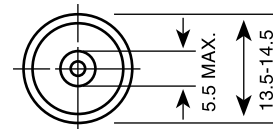

Unit : mm

The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.