

## Connector set - HC-EVO-B16PT-BWD-HH-M25ELC-AL - 1411489

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



EVO connector set, B16 series, metal housing, consisting of: sleeve housing 1411460, panel mounting base 1411327, EVO screw connection 1411446, pin contact insert 1407732, socket contact insert 1407731

RoHS

### Key Commercial Data

Packing unit	1 pc
GTIN	 4 046356 932899
GTIN	4046356932899
Weight per Piece (excluding packing)	622.500 g
Custom tariff number	85366990
Country of origin	Germany

### Technical data

#### General

Number of positions	16+PE
Type	B16
Connection method	Push-in connection
Cable outlet	straight
	lateral
Degree of protection for housing	IP66
	IP67
	4 (UL 50e)
	4X (UL 50e)
	12 (UL 50e)
Connection method	Push-in connection
Rated voltage (III/3)	500 V
Rated surge voltage	6 kV
Rated current	16 A

# Connector set - HC-EVO-B16PT-BWD-HH-M25ELC-AL - 1411489


## Technical data

### Standards and Regulations


Flammability rating according to UL 94	V0
Environmental Product Compliance	
REACH SVHC	Lead 7439-92-1

## Drawings

Schematic diagram

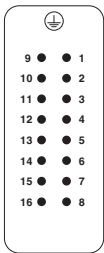


Schematic diagram

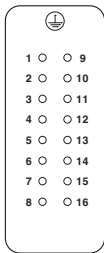

Pin assignment, connection side, pin


Pin assignment, connection side, socket

Diagram

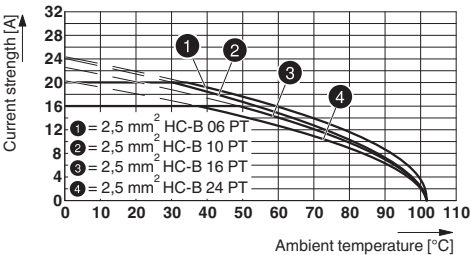


Derating diagram

Dimensional drawing

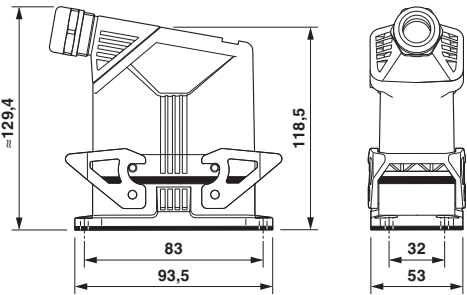

Dimensional drawing

Dimensional drawing

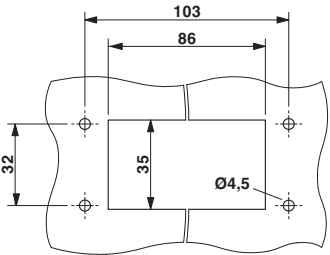

Mounting cutout

## Connector set - HC-EVO-B16PT-BWD-HH-M25ELC-AL - 1411489

### Articles in set

Contact insert - HC-B16-I-PT-F - 1407731



HEAVYCON socket insert, B16 series, 16 + PE-pos., push-in connection

Contact insert - HC-B16-I-PT-M - 1407732



HEAVYCON pin insert, B16 series, 16 + PE-pos., push-in connection

Cable gland - HC-B-G-M25-EC-AL - 1411446



EVO EMC cable gland with bayonet locking, B series, size M25, cable diameter: 11 - 16 mm

Housing - HC-STA-B16-BWD-ELC-AL - 1411327



HEAVYCON B16 panel mounting base, with double locking latch, with flat gasket, salt-water-resistant aluminum, conductive profile gasket

Housing - HC-EVO-B16-HHFD-EL-AL - 1411460



HEAVYCON EVO sleeve housing, EMC version, without powder coating, with bayonet flange for EVO screw connection, B16, for double locking latch, height: 88 mm, without EVO screw connection.

### Classifications

eCl@ss

eCl@ss 5.1	27260700
eCl@ss 6.0	27260700

## Connector set - HC-EVO-B16PT-BWD-HH-M25ELC-AL - 1411489

### Classifications

#### eCl@ss

eCl@ss 7.0	27440101
eCl@ss 8.0	27440101
eCl@ss 9.0	27440101

#### ETIM

ETIM 4.0	EC002641
ETIM 5.0	EC002636
ETIM 6.0	EC002636

#### UNSPSC

UNSPSC 13.2	39121409
-------------	----------

### Approvals

#### Approvals


#### Approvals

#### GL / EAC

#### Ex Approvals

### Approval details

GL		<a href="http://exchange.dnv.com/tari/">http://exchange.dnv.com/tari/</a>	6196614 HH
----	---	---	------------

EAC		RU C- DE.AI30.B.01102
-----	---	--------------------------

### Accessories

#### Accessories

#### Device marking

Plastic label - US-EMLP-HA (20X9) - 0830989



Plastic label, Card, white, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: adhesive, lettering field size: 20 x 9 mm

## Connector set - HC-EVO-B16PT-BWD-HH-M25ELC-AL - 1411489

### Accessories

---

#### Housing latches

Double locking latch - HC-B10-24-DL-PLBK - 1407696



Replacement double locking latch for HEAVYCON EVO housing, HC-B10/HC-B16/HC-B24, PA

---