


Professionally approved products.

Product Datasheet

Polyethylene Terminal Blocks


EN

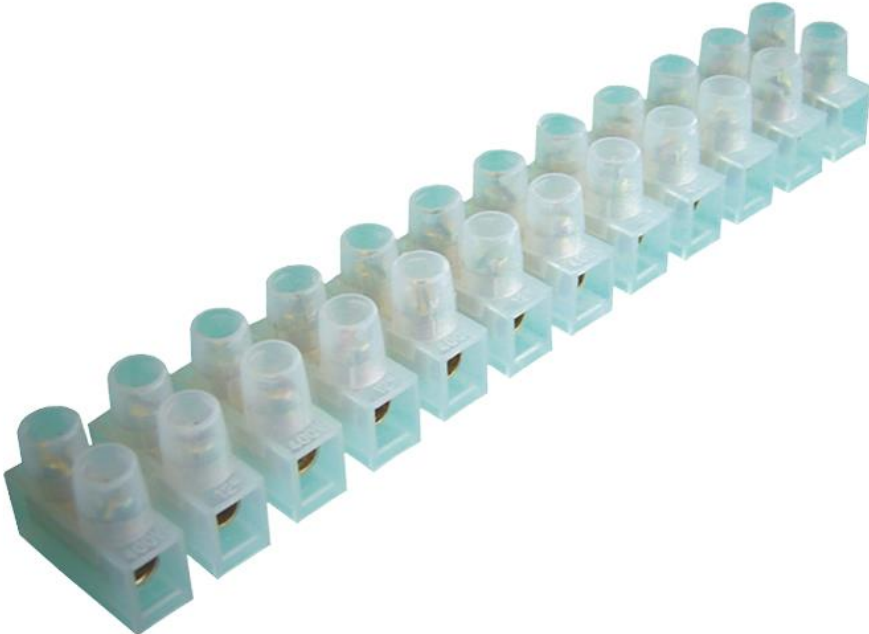

SPECIFICATION**HOUSING:** POLYETHYLENE (PE)**INSERTS:** BRASS**SCREWS:** GALVANISED STEEL**TEMP.:** 80°C**COLOR:** NATURAL**STANDARD:** CE**FEATURES:**

EASY-CUT & LOW-COST

ALL SCREWS ARE CAPTIVE & RAISED FOR EASY WIRING

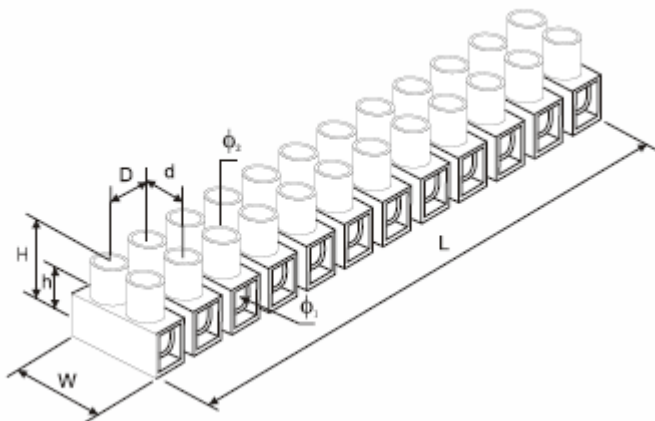DIMENSIONS



RS CODE	CROSS SECTION	CURRENT RANGE	RATED VOLTAGE	DIMENSIONS (mm)							
				L	W	Φ1	Φ2	D	d	H	h
7638113	4 mm ²	3~24A	380V	93	16.8	2.8	2.3	7.8	6	13.6	7.6
7638116	6 mm ²	5~32A	380V	115	18.8	3.3	2.6	10	8	15	8.8
8670963	10 mm ²	10~57A	400V	129	20.7	4.3	2.8	11	9	16.2	9.6
8670972	12 mm ²	15~61A	400V	137	22.5	4.5	2.8	12	10	18.8	10.2
8670975	16 mm ²	30~76A	400V	165	25.5	5.5	3	14	11	19.8	11.2
8670979	25mm ²	60~101A	400V	187	31.2	6.5	3.8	16.5	13	25.5	14.8
Cross Section:	rated for rigid wire and cables (if for flexible wire, it should be reduced one-step, i.e. 6mm ² is 4mm ² Φ1 wire entry hole diameter Φ2 fixing hole diameter										