


PXMBNI12FIM05BSCPG7 Datasheet



Product Name // M12 Series B Code Brass Nickel Plated
PG7 Inline Body 5 Contact Pins

View Product Page

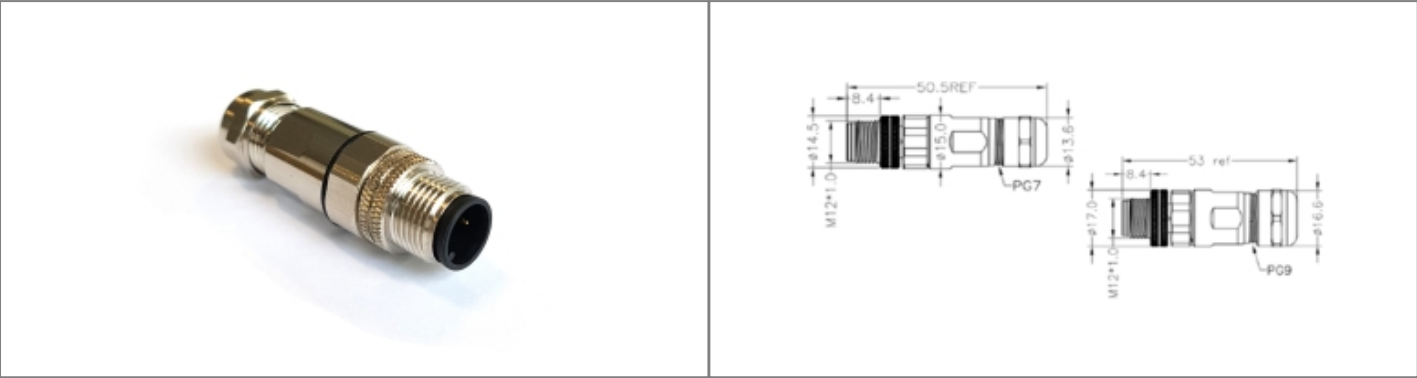

// Product Description:

M12 Series Brass Nickel Plated Inline Body Connectors

Water and dustproof to IP67 when mated with compatible connector

Pin only

3, 4, 5, 8, 12 Contact (3, 8, 12 Contact are A Code, 4 Contact are choice of A Code A or D Code, 5 Contact are choice of A Code or B Code)

Solder Terminals

Choice of gland nut sizes, depending on part code

Choice of Sealing Caps available separately to maintain IP rating of unmated connectors

Mate with M12 Series Flex Body and Panel Mount Connectors

// General Information:

Product Display Title:

Product Family:

Product Series:

Approvals:

Body Material:

Contact Type:

Coupling Type:

Current Max:

Diameter Over Coupling Ring Mm:

Function:

Ip Rating:

M12 Series Mounting Nut:

Max Operating Temperature:

Min Operating Temperature:

Number Of Contacts:

Pin Layout Code:

Thread Size:

Voltage Max:

M12 Series Brass Nickel Plated Inline Body Connectors

Circular Automation Connectors

M12 Series

CSA, UL

Brass - Nickel Plated

Plug Contact

Screw

4A

20mm

Inline Cable Connector Body

IP67

PG7

+80°C

-25°C

5 Contacts

B Code

M12 x 1

60V

// Product PDF Links

M12 Series automation connectors...

// Product 3D CAD Model Links

PXMBNI12FIM05BSCPG73D CAD Model