


R.ET – ¼" 12 Point Sockets

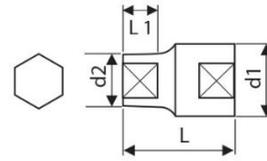

Description:

- **12-Point OGV® Profile** – Maximising the contact surface with the nut and minimising damage to the fastener
- **NECK-DOWN DESIGN** - Facilitating the use in narrow spaces
- **Matte finish**
- **ASME B107.1, ASME B107.110**

	Fastener Size (inch)	Square Drive	Length L1 (mm)	Diameter D2 (mm)	Weight (g)
R.3/16ET	3/16	¼"	22	11	8
R.7/32ET	7/32	¼"	22	11	8
R.1/4ET	¼	¼"	22	11	8
R.9/32ET	9/32	¼"	22	11	10
R.5/16ET	5/16	¼"	22	11	10
R.11/32ET	11/32	¼"	22	13	12
R.3/8ET	3/8	¼"	22	14.7	16
R.7/16ET	7/16	¼"	22	15.8	16
R.1/2ET	½	¼"	22	17.2	22
R.9/16ET	9/16	¼"	22	18.7	24