


DX08WB024N Datasheet

Product Name // DX08WB024N, 8mm Diameter, Wire Leads 200mm, Blue, 24V, Nickel Plated Brass

 [View Product Page](#)

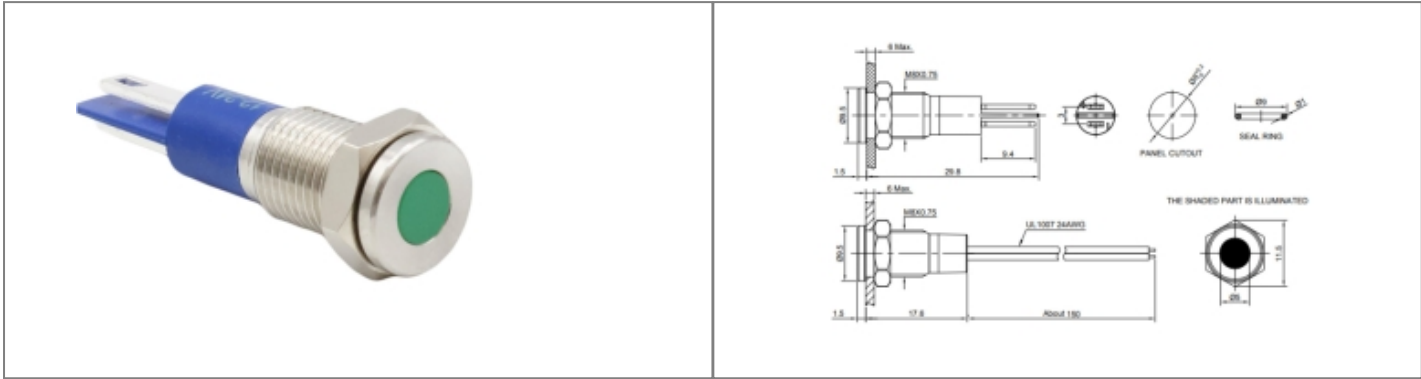

// Product Description:

- | | |
|--|---|
|  DX Range |  Blue |
|  8mm Diameter |  24V |
|  Wire Leads 200mm |  Nickel Plated Brass |

// General Information:

Product Display Title:	8mm Vandal Resistant Indicator DX Range
Product Family:	Indicators
Product Series:	8mm Vandal Resistant Indicator DX Range
Bezel Finish:	Polished
Body Colour:	Nickel
Body Material:	Brass
Body Material Type:	Metal
Diameter:	8mm
Dielectric Withstanding Voltage:	1500V
Function:	Vandal Resistant Indicator
Illumination Colour:	Blue
Illumination Voltage:	24V
Indicator Profile:	Flat-round
Insulation Resistance:	≥100MΩ(500VDC)
Ip Rating:	IP67
Material Finish:	Polished
Max Operating Temperature:	55°C
Min Operating Temperature:	-25°C
Max Panel Thickness:	6mm
Panel Cut Out:	8mm Diameter Circle
Rohs Compliant:	Yes
Thread Size:	M8 X 0.75

// Product PDF Links

 [6mm & 8mm Vandal Resistant...](#)

// Product 3D CAD Model Links

 [DX08WB024N3D CAD Model](#)



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)