

I.680 SOFT

SOFT

ELESA original design

Handles



• Material

High-resilience polypropylene based (PP) technopolymer, coated with "soft-touch" thermoplastic elastomer (TPE) chemically bonded, hardness 70 Shore A.

The coating material is certified in compliance with FDA (U.S. Food and Drug Administration).

Resistant to solvents, oils, greases and other chemical agents.

• Colour


Black, matte finish.

• Standard execution

Threaded blind hole.

Features and applications

The coating, with "soft-touch" elastomer, improves the grip even in the presence of oils, greases and sweat from the hand. For this reason it is suitable for fitness machines, tools and machines for gardening and goods transport, high-precision instruments and disability aids.

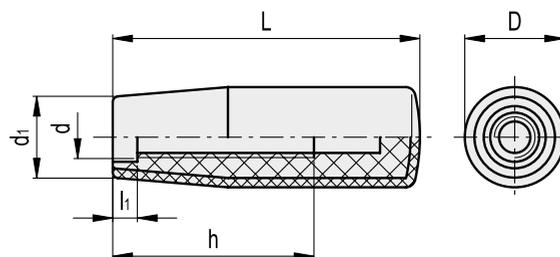

Code	Description	D	L	d	d1	h	l1	⚖
124861	I.680/65-M8 SOFT	24.5	65	M8	20.5	30	7	34
124862	I.680/65-M10 SOFT	24.5	65	M10	20.5	40	7	-
124864	I.680/80-M8 SOFT	26.5	80	M8	21	40	7	46
124865	I.680/80-M10 SOFT	26.5	80	M10	21	55	7	45
124866	I.680/80-M12 SOFT	26.5	80	M12	21	55	7	44
124871	I.680/90-M10 SOFT	28.5	90	M10	22	56	7	51
124872	I.680/90-M12 SOFT	28.5	90	M12	22	58	10	50