

QPD P 4PE2,5 6-11 TL BK - Connector



1039563

<https://www.phoenixcontact.com/in/products/1039563>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Connector, product family: QPD, connection method: IDC connection, number of positions: 4+PE, 1 mm² ... 2.5 mm², 690 V, 20 A, PA, black, with QUICKON nut, external cable diameter: 6 mm ... 11 mm

Your advantages

- Innovative and time saving - QUICKON fast connection for time saving of up to 80 % for on-site connection
- Robust throughout: housing with IP68/IP69K and IK07 protection for a wide range of applications
- Safer connection with mechanical coding to protect against mismatching, and touch-proof protection in accordance with DIN EN 0105
- Easy maintenance – the connectors enable fast device replacement and preassembled cables simplify startup

Commercial data

Item number	1039563
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF6
Product key	AF6BCB
Catalog page	Page 487 (C-2-2019)
GTIN	4055626596297
Weight per piece (including packing)	73.9 g
Weight per piece (excluding packing)	74 g
Customs tariff number	85366990
Country of origin	PL

QPD P 4PE2,5 6-11 TL BK - Connector



1039563

<https://www.phoenixcontact.com/in/products/1039563>

Technical data

Product properties

Product type	Installation connector
Product family	QPD
Type	QPD 5x2,5
Number of positions	5
Connection profile	4+PE
Position marking	1, 2, 3, N, PE
Number of connections	10
Number of connections per position	1

Insulation characteristics

Overvoltage category	III
Degree of pollution	3

Electrical properties

Rated surge voltage (II/2)	8 kV
Rated surge voltage (III/2)	8 kV
Rated surge voltage (III/3)	6 kV
Rated current	20 A
Contact resistance	< 4 mΩ
rated voltage (II/2)	1000 V
rated voltage (III/2)	1000 V
Rated voltage (III/3)	690 V
Nominal voltage U_N	690 V
Nominal current I_N	20 A

Connection data

Connection technology

Connection method On the field side	IDC connection
Frequency of connections between conductors of the same cross section	max. 10

Conductor connection

Conductor cross section flexibel	1 mm ² ... 2.5 mm ²
Conductor cross section solid	1 mm ² ... 2.5 mm ²
Connection cross section AWG	16 ... 14
Tightening torque Union nut	10 Nm
Wrench size Union nut	27 mm

Dimensions

Width	34.6 mm
Height	39.1 mm

QPD P 4PE2,5 6-11 TL BK - Connector



1039563

<https://www.phoenixcontact.com/in/products/1039563>

Length	87.8 mm
Diameter	39.1 mm

Material specifications

Color	black (RAL 9005)
Material Housing	PA
Material Contact surface	silver-plated
Flammability rating according to UL 94	V0
Material wire insulation	PVC/PE/TPE/rubber

Cable/line

Structure of individual litz in acc. with VDE 0295 / smallest wire diameter	VDE 0295 class 1 to 6/min. 0.15 mm
External cable diameter	6 mm ... 11 mm
Wire diameter including insulation	2 mm ... 3.8 mm
Position marking	1, 2, 3, N, PE
Material wire insulation	PVC/PE/TPE/rubber

Mechanical properties

Mechanical data


Insertion/withdrawal cycles	max. 50
-----------------------------	---------

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP66
	IP68 (2 m / 24 h)
	IP69K
	Touch-proof when not plugged in (IP2X)
Impact strength	IK07
Ambient temperature (operation)	-40 °C ... 100 °C
Temperature when conductor connected	-5 °C ... 50 °C
Ambient temperature (storage/transport)	-40 °C ... 100 °C

Drawings

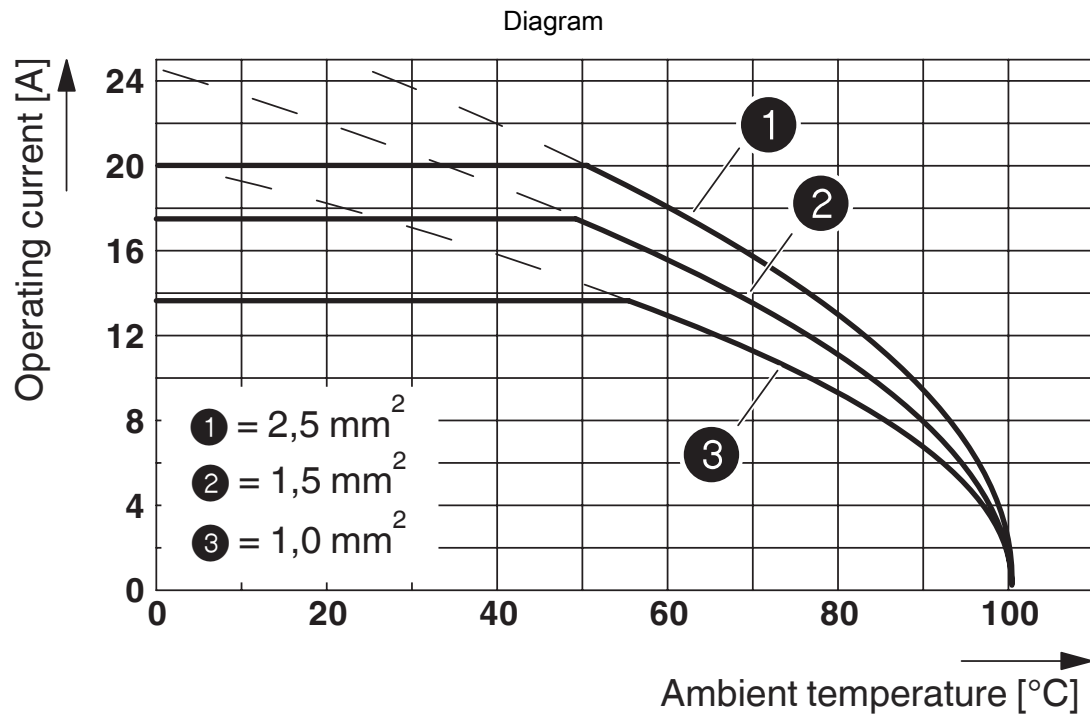

QPD P 4PE2,5 6-11 TL BK - Connector



1039563

<https://www.phoenixcontact.com/in/products/1039563>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/1039563>



IECEE CB Scheme

Approval ID: DE1-65875



VDE approval of drawings

Approval ID: 40029149



UL Listed

Approval ID: E468743

	Nominal voltage U_N	Nominal current I_N	Cross section AWG	Cross section mm^2
	600 V	10 A	-	- 14



cUL Listed

Approval ID: E468743

	Nominal voltage U_N	Nominal current I_N	Cross section AWG	Cross section mm^2
	600 V	10 A	- 14	-

cULus Listed

QPD P 4PE2,5 6-11 TL BK - Connector



1039563

<https://www.phoenixcontact.com/in/products/1039563>

Classifications

ECLASS

ECLASS-11.0	27440605
ECLASS-12.0	27440605
ECLASS-13.0	27440605

ETIM

ETIM 9.0	EC002560
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

QPD P 4PE2,5 6-11 TL BK - Connector

1039563

<https://www.phoenixcontact.com/in/products/1039563>



Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

QPD P 4PE2,5 6-11 TL BK - Connector

1039563

<https://www.phoenixcontact.com/in/products/1039563>



Mandatory accessories

QPD W 4PE2,5 6-11 M20 0,5 BK - Panel feed-through

1403725

<https://www.phoenixcontact.com/in/products/1403725>



Panel feed-through, product family: QPD, connection method: Single wires (Welded-on)/ IDC connection, number of positions: 4+PE, M20, Pin, 1 mm² ... 2.5 mm², 690 V, 20 A, PA, black, with QUICKON nut, coding: coded, external cable diameter: 6 mm ... 11 mm, 2.5 mm², wires cut flat at the end, cable length: 0.5 m

QPD W 4PE2,5 6-11 M20 1,0 BK - Panel feed-through

1403727

<https://www.phoenixcontact.com/in/products/1403727>



Panel feed-through, product family: QPD, connection method: Single wires (Welded-on)/ IDC connection, number of positions: 4+PE, M20, Pin, 1 mm² ... 2.5 mm², 690 V, 20 A, PA, black, with QUICKON nut, coding: coded, external cable diameter: 6 mm ... 11 mm, 2.5 mm², wires cut flat at the end, cable length: 1 m

QPD P 4PE2,5 6-11 TL BK - Connector

1039563

<https://www.phoenixcontact.com/in/products/1039563>



QPD W 4PE2,5 6-11 M20 FC BK - Panel feed-through

1403729

<https://www.phoenixcontact.com/in/products/1403729>



Panel feed-through, product family: QPD, connection method: Spade connection (For slip-on sleeves according to DIN 46247-2)/ IDC connection, number of positions: 4+PE, M20, Pin, 1 mm² ... 2.5 mm², 690 V, 20 A, PA, black, with QUICKON nut, coding: coded, external cable diameter: 6 mm ... 11 mm

QPD W 4PE2,5 6-11 M25 0,5 BK - Panel feed-through

1582557

<https://www.phoenixcontact.com/in/products/1582557>



Panel feed-through, product family: QPD, connection method: Single wires (Welded-on), number of positions: 4+PE, M25, Pin, 1 mm² ... 2.5 mm², 690 V, 20 A, PA, black, with QUICKON nut, coding: coded, external cable diameter: 6 mm ... 11 mm, 2.5 mm², wires cut flat at the end, cable length: 0.5 m

QPD P 4PE2,5 6-11 TL BK - Connector

1039563

<https://www.phoenixcontact.com/in/products/1039563>



QPD W 4PE2,5 6-11 M25 1,0 BK - Panel feed-through

1582558

<https://www.phoenixcontact.com/in/products/1582558>



Panel feed-through, product family: QPD, connection method: Single wires (Welded-on), number of positions: 4+PE, M25, Pin, 1 mm² ... 2.5 mm², 690 V, 20 A, PA, black, with QUICKON nut, coding: coded, external cable diameter: 6 mm . . . 11 mm, 2.5 mm², wires cut flat at the end, cable length: 1 m

QPD W 4PE2,5 6-11 M25 FC BK - Panel feed-through

1582559

<https://www.phoenixcontact.com/in/products/1582559>



QUICKON panel feed-through, black, 4+PE-pos. 1.0 mm² ... 2.5 mm²/690 V/20 A, with QUICKON nut, for 6 mm ... 11 mm cable diameter, M25 connection thread with 5 slip-on contacts for slip-on sleeves according to DIN 46247-2

QPD P 4PE2,5 6-11 TL BK - Connector

1039563

<https://www.phoenixcontact.com/in/products/1039563>



QPD W 4PE2,5 6-11 M25 DT BK - Panel feed-through

1411432

<https://www.phoenixcontact.com/in/products/1411432>



Panel feed-through, product family: QPD, connection method: Push-in connection/ IDC connection, number of positions: 4+PE, M25, Pin, 1 mm² ... 2.5 mm², 690 V, 20 A, PA, black, with QUICKON nut, coding: coded, external cable diameter: 6 mm ... 11 mm

QPD C 4PE2,5 1X6-11 BK - Conductor connector

1403834

<https://www.phoenixcontact.com/in/products/1403834>



QUICKON cable connector, black, 4+PE-pos., 1.0 mm² ... 2.5 mm² / 690 V / 20 A, for 6 mm ... 11 mm cable diameter.

QPD P 4PE2,5 6-11 TL BK - Connector

1039563

<https://www.phoenixcontact.com/in/products/1039563>



QPD C 4PE2,5 2X6-11 BK - Conductor connector

1403838

<https://www.phoenixcontact.com/in/products/1403838>



QUICKON cable connector, black, 4+PE-pos., 1.0 mm² ... 2.5 mm² / 690 V / 20 A, for 6 mm ... 11 mm cable diameter.

QPD T 4PE 2X6-11 BK - T distributor

1405403

<https://www.phoenixcontact.com/in/products/1405403>



QUICKON T-distributor, black, 4+PE-pos., 1.0 mm² ... 2.5 mm²/690 V/20 A, for cable diameter of 6 mm ... 11 mm, with two QUICKON nuts

QPD P 4PE2,5 6-11 TL BK - Connector

1039563

<https://www.phoenixcontact.com/in/products/1039563>



QPD T 4PE 3X6-11 BK - T distributor

1405401

<https://www.phoenixcontact.com/in/products/1405401>



T distributor, product family: QPD, connection method: IDC connection, number of positions: 4+PE, 1 mm² ... 2.5 mm², 690 V, 20 A, PA, black, With three QUICKON nuts, coding: Coding profile, external cable diameter: 6 mm ... 11 mm

QPD H 4PE2,5 4X6-11 BK - H distributor

1406368

<https://www.phoenixcontact.com/in/products/1406368>



QUICKON H-distributor, black, 4 pos. +PE, 1.0 mm² ... 2.5 mm² / 690 V / 20 A, for cable diameters of 6 mm ... 11 mm, with a sealing bolt.

QPD P 4PE2,5 6-11 TL BK - Connector

1039563

<https://www.phoenixcontact.com/in/products/1039563>



QPD W 4PE2,5 M20 0,5 BK - Panel feed-through

1403737

<https://www.phoenixcontact.com/in/products/1403737>



Panel feed-through, product family: QPD, connection method: Single wires (Welded-on), number of positions: 4+PE, M20, Pin, 1 mm² ... 2.5 mm², 690 V, 20 A, PA, black, without QUICKON nut, coding: coded, 2.5 mm², wires cut flat at the end, cable length: 0.5 m

QPD W 4PE2,5 M20 1,0 BK - Panel feed-through

1403739

<https://www.phoenixcontact.com/in/products/1403739>



Panel feed-through, product family: QPD, connection method: Single wires (Welded-on), number of positions: 4+PE, M20, Pin, 1 mm² ... 2.5 mm², 690 V, 20 A, PA, black, without QUICKON nut, coding: coded, 2.5 mm², wires cut flat at the end, cable length: 1 m

QPD P 4PE2,5 6-11 TL BK - Connector

1039563

<https://www.phoenixcontact.com/in/products/1039563>



QPD W 4PE2,5 M20 FC BK - Panel feed-through

1403741

<https://www.phoenixcontact.com/in/products/1403741>



Panel feed-through, product family: QPD, connection method: Spade connection (For slip-on sleeves according to DIN 46247-2), number of positions: 4+PE, M20, Pin, 1 mm² ... 2.5 mm², 690 V, 20 A, PA, black, without QUICKON nut, coding: coded

QPD W 4PE2,5 M25 0,5 BK - Panel feed-through

1582565

<https://www.phoenixcontact.com/in/products/1582565>



Panel feed-through, product family: QPD, connection method: Single wires (Welded-on), number of positions: 4+PE, M25, Pin, 1 mm² ... 2.5 mm², 690 V, 20 A, PA, black, without QUICKON nut, coding: coded, 2.5 mm², wires cut flat at the end, cable length: 0.5 m

QPD P 4PE2,5 6-11 TL BK - Connector

1039563

<https://www.phoenixcontact.com/in/products/1039563>



QPD W 4PE2,5 M25 1,0 BK - Panel feed-through

1582566

<https://www.phoenixcontact.com/in/products/1582566>



Panel feed-through, product family: QPD, connection method: Single wires (Welded-on), number of positions: 4+PE, M25, Pin, 1 mm² ... 2.5 mm², 690 V, 20 A, PA, black, without QUICKON nut, coding: coded, 2.5 mm², wires cut flat at the end, cable length: 1 m

QPD W 4PE2,5 M25 FC BK - Panel feed-through

1582567

<https://www.phoenixcontact.com/in/products/1582567>



Panel feed-through, product family: QPD, connection method: Spade connection (For slip-on sleeves according to DIN 46247-2), number of positions: 4+PE, M25, Pin, 1 mm² ... 2.5 mm², 690 V, 20 A, PA, black, without QUICKON nut, coding: coded

QPD P 4PE2,5 6-11 TL BK - Connector

1039563

<https://www.phoenixcontact.com/in/products/1039563>



QPD H 4PE2,5 BK - H distributor

1406370

<https://www.phoenixcontact.com/in/products/1406370>



QUICKON H-distributor, black, 4+PE pos., 690 V/20 A, without QUICKON nut

Accessories

CP-QPD 5X2,5 - Coding profile

1404530

<https://www.phoenixcontact.com/in/products/1404530>



Coding profile, red, for insertion into the 5-pos. QUICKON dome and connector, can be positioned in 72° increments.

QPD P 4PE2,5 6-11 TL BK - Connector

1039563

<https://www.phoenixcontact.com/in/products/1039563>



QPD QSK 5X2,5 - Protective cap

1404528

<https://www.phoenixcontact.com/in/products/1404528>

Protective cap, transparent plastic, for 5x 2.5 mm² QPD QUICKON connection, IP50.



QPD PSK 5X2,5 - Protective cap

1404529

<https://www.phoenixcontact.com/in/products/1404529>

Protective cap, transparent plastic, for 5 x 2.5 mm² QPD connector, IP50.



QPD P 4PE2,5 6-11 TL BK - Connector

1039563

<https://www.phoenixcontact.com/in/products/1039563>



SEALING PLUG 10X16 RD - Sealing plug

1400284

<https://www.phoenixcontact.com/in/products/1400284>

Sealing plug, for threads pluggable, color: red



QPD P 4PE2,5 6-11 BK - Connector

1403784

<https://www.phoenixcontact.com/in/products/1403784>



Connector, product family: QPD, connection method: IDC connection, number of positions: 4+PE, 1 mm² ... 2.5 mm², 690 V, 20 A, PA, black, external cable diameter: 6 mm ... 11 mm

QPD P 4PE2,5 6-11 TL BK - Connector

1039563

<https://www.phoenixcontact.com/in/products/1039563>



QPD N 4PE2,5 6-11 BK - Nut

1459663

<https://www.phoenixcontact.com/in/products/1459663>



QUICKON nut, black, 4+PE-pos., 1.0 mm² ... 2.5 mm²/690 V/20 A, for cables with 6 mm ... 11 mm diameter.

QSS 27 - Socket wrench

1670646

<https://www.phoenixcontact.com/in/products/1670646>



Allen wrench, for loosening and fastening the QUICKON union nut, WAF 27 mm

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

info@phoenixcontact.co.in