


FIBOX
Enclosing innovations



Remarks : Openings: 8x size 2 flange

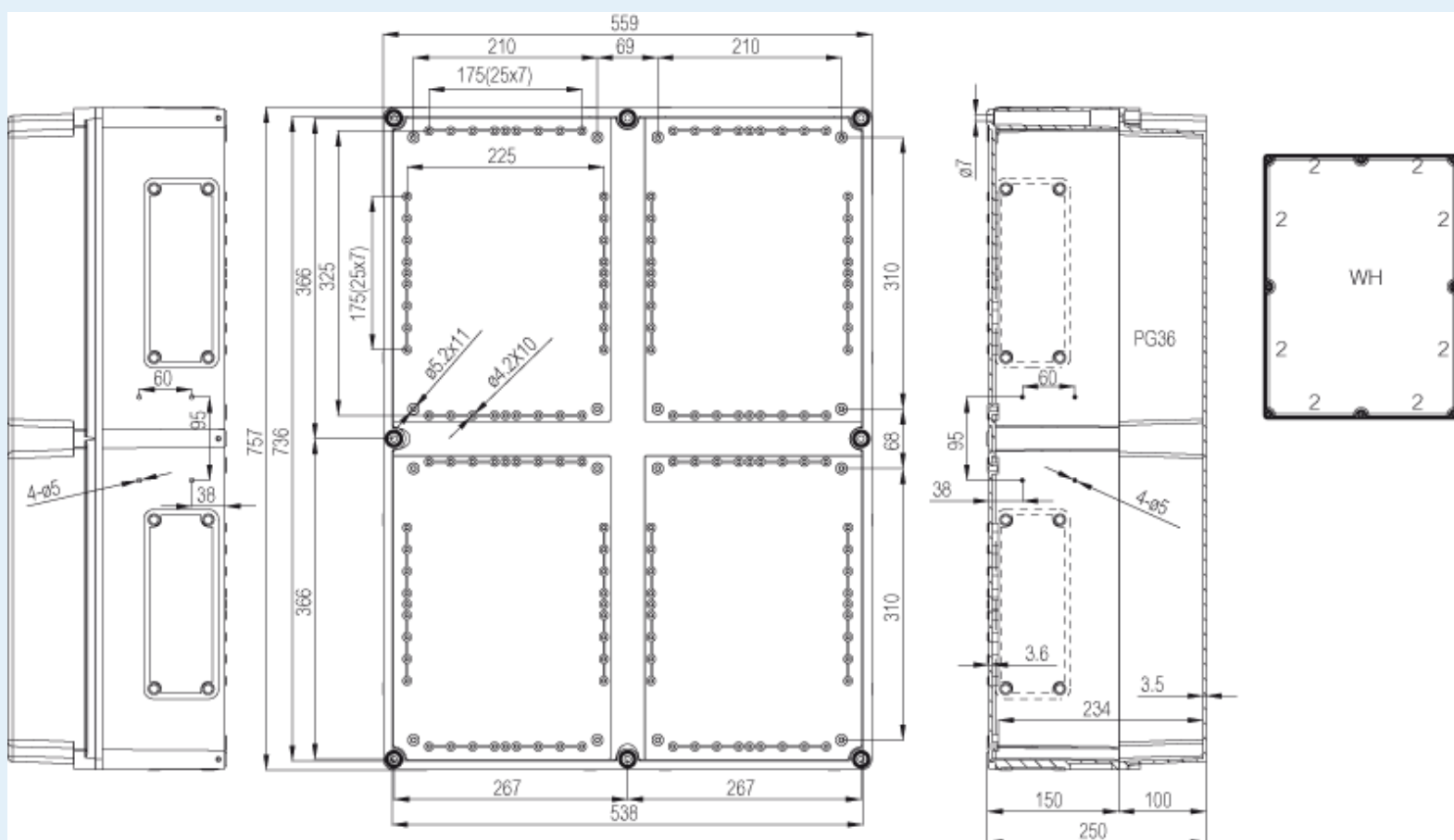

Dimensions :	Height	Width	Depth
mm :	760	560	150
inch :	29.92	22.05	5.91

Accessories :

EKUVT	Mounting plate, for enclosures: (518 x 338 x 1.5)
-------	--

Materials :

Material : Polycarbonate

Base colour : RAL_7035

Temperatures :

Temperature °C (continuous) : -40 ... 80

Temperature °F (continuous) : -40 ... 175

Ratings :

electrical_insulation : Totally insulated

UV resistance : UL 746C

Flammability Rating : UL 94 V0

Glow Wire Test (IEC 695-2-1) °C : 960C

Certificates :

SGSFIMKO_EK