


Trade LED flush bulkhead with sensor



MLA part code	BT14S	BT14DS
Description	TRADE LED FLUSH + SENSOR	
Net weight (kg)	0.8	
Wattage (W)	14	
Lumens (lm)	910 ± 5%	1030 ± 5%
Efficacy (lm/W)	65	73
Overall dimensions	Diameter – 315mm Projection – 74mm	
CCT	4000K	6000K
LED Colours	Cool white	Daylight
Input voltage	Mains 230V 50Hz	
Construction	Polycarbonate	
Finish	White	
Diffuser	Opal	
Sensor type	Microwave	
Class	Class II double insulated	
IP rating	IP44	
Warranty	3 Years	
Lamp replacement available	Yes (BT14DL)	
Photometric data	Yes	
Dimmable	No	
Origin of Manufacture	China	
Quality assurance system	ISO9001	
Declaration of Conformity (held on file)	Yes	
Manufactured & accordance with	BS EN 60598	
EAN	5055832901228	5055832938408

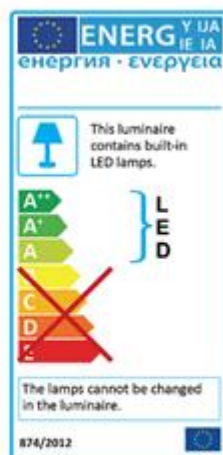