




MASTER PL-T /4P (continued)

Wattage/ Colour Code	Cap-Base	Colour Rendering Index (R _a)		Luminous Flux EL 25°C, Rated (lm)	Dimmable	Life to 10% fail Preheat EL,3h (h)	Life to 50% fail Preheat EL,3h (h)	Dim. no.	Packing type/ Packing configuration		National Order Code	Ordering number 87 11 500...	
18W/840	GX24q-2	82	B	1,200	yes	8,000	13,000	3	ICT / 5X10CC	50	18PLT8404PINCS	61099770	yes
26W/827	GX24q-3	82	B	1,725	yes	8,000	13,000	4	ICT / 5X10CC	50	26PLT8274PINCS	55993770	yes
26W/830	GX24q-3	83	B	1,725	yes	8,000	13,000	4	ICT / 5X10CC	50	26PLT8304PINCS	61120870	yes
26W/840	GX24q-3	82	B	1,725	yes	8,000	13,000	4	ICT / 5X10CC	50	26PLT8404PINCS	61125370	yes
32W/827	GX24q-3	82	B	2,400	yes	8,000	13,000	5	ICT / 5X10CC	50	32PLT8274PINCS	55996870	yes
32W/830	GX24q-3	82	B	2,400	yes	8,000	13,000	5	ICT / 5X10CC	50	32PLT8304PINCS	61128470	yes
32W/840	GX24q-3	82	B	2,400	yes	8,000	13,000	5	ICT / 5X10CC	50	32PLT8404PINCS	61131470	yes
42W/830	GX24q-4	82	B	3,050	yes	8,000	13,000	6	ICT / 5X10CC	50	42PLT8304PINCS	61134570	yes
42W/840	GX24q-4	82	B	3,050	yes	8,000	13,000	6	ICT / 5X10CC	50	42PLT8404PINCS	61137670	yes
57W/830	GX24q-5	82	B	4,200	yes	8,000	13,000	2	ICT / 5X10CC	50	57PLT8304PINCS	61140670	yes
57W/840	GX24q-5	82	B	4,200	yes	8,000	13,000	2	ICT / 5X10CC	50	57PLT8404PINCS	61145170	yes

MASTER PL-T TOP 4 Pin



Product Description

- Energy saving compact fluorescent lamp

- Compact long-arc low-pressure mercury discharge lamp
- Envelope consists of 6 parallel narrow fluorescent tubes
- Amalgam controlled operation

Product Features

- 4-pin base without glow switch starter and capacitor
- Hot restrike - moderate light run up after cooling down at low temperatures
- Optimized lighting performance over a broad temperature range due to Philips amalgam technology
- Dimming is possible

Product Benefits

- Optimal lighting performance for long periods of continuous operation

- Substantially higher light output (+30%) per light point than conventional solutions
- High temperature independency at higher application temperatures
- Long life and sustainable light output

Environment


- Good environmental choice because of high energy efficiency, long life and low light output depreciation, lowest mercury content
- Compliant with all RoHS and WEEE requirements: the lamps have a very low content of mercury, are lead free and make no use of radioactive materials and hazardous flame retardants

Application


- Designed for general or supplementary lighting in professional and semi-professional environments
- Ideal for use in recessed or surface mounted downlighters, wall units
- First choice for long switching cycles and highest light output

Warnings and Safety


- Lamp light technical and electrical characteristics are influenced by operating conditions, i. e. lamp ambient temperature and operating position as well as applied HF control gear
- Shorter lamp life when often switching and not well pre-heated electrodes

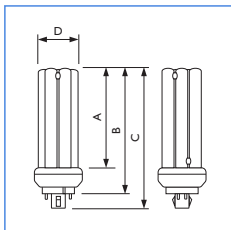

Dim. no.	A max.	B max.	C max.	D max.
1	86.7	111	126.7	41

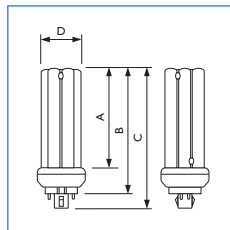

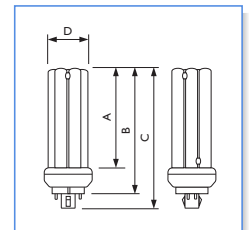


Dim. no.	A max.	B max.	C max.	D max.
2	120.7	145	160.7	41



Dim. no.	A max.	B max.	C max.	D max.
3	157.7	182	197.7	41

MASTER PL-T TOP /4P

Wattage/ Colour Code	Cap-Base	Colour Rendering Index (R _a)		Luminous Flux EL 25°C, Rated (lm)	Dimmable	Life to 10% fail Preheat EL,3h (h)	Life to 50% fail Preheat EL,3h (h)	Dim. no.	Packing type/ Packing configuration		National Order Code	Ordering number 87 11 500...	
26W/830	GX24q-3	82	B	1,725	yes	8,000	13,000	1	ICT / 5X10CC	50	26PLT8304PINTOP	88944770	yes
26W/840	GX24q-3	82	B	1,725	yes	8,000	13,000	1	ICT / 5X10CC	50	26PLT8404PINTOP	88947870	yes
42W/830	GX24q-4	82	B	3,050	yes	8,000	13,000	2	ICT / 5X10CC	50	42PLT8304PINTOP	61004170	yes
42W/840	GX24q-4	82	B	3,050	yes	8,000	13,000	2	ICT / 5X10CC	50	42PLT8404PINTOP	61008970	yes
57W/830	GX24q-5	82	B	3,900	yes	8,000	13,000	3	ICT / 5X10CC	50	57PLT8304PINTOP	61022570	yes
57W/840	GX24q-5	82	B	3,900	yes	8,000	13,000	3	ICT / 5X10CC	50	57PLT8404PINTOP	61034870	yes