



SETRON, cylindrical fuse link, 10x85 mm, 4 A, gPV, Un DC: 1500 V

Figure similar


Model		
product brand name		SETRON
product designation		Cylindrical fuse link
General technical data		
operating class of the fuse link		gPV
type of voltage of the operating voltage		DC
supply voltage at DC		1 500 V
Main circuit		
operational current rated value		4 A
Product details		
product component striker		No
Mechanical Design		
mounting position		Any, preferably vertical
net weight		15 g
Approvals Certificates		
General Product Approval	other	Environment



[Confirmation](#)

[Environmental Con-
firmations](#)

Further information	
Information on the packaging	https://support.industry.siemens.com/cs/ww/en/view/109813875
Information- and Downloadcenter (Catalogs, Brochures,...)	http://www.siemens.com/lowvoltage/catalogs
Industry Mall (Online ordering system)	https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NW6604-4
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)	https://support.industry.siemens.com/cs/ww/en/ps/3NW6604-4
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)	http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NW6604-4
CAX-Online-Generator	http://www.siemens.com/cax
Tender specifications	http://www.siemens.com/specifications

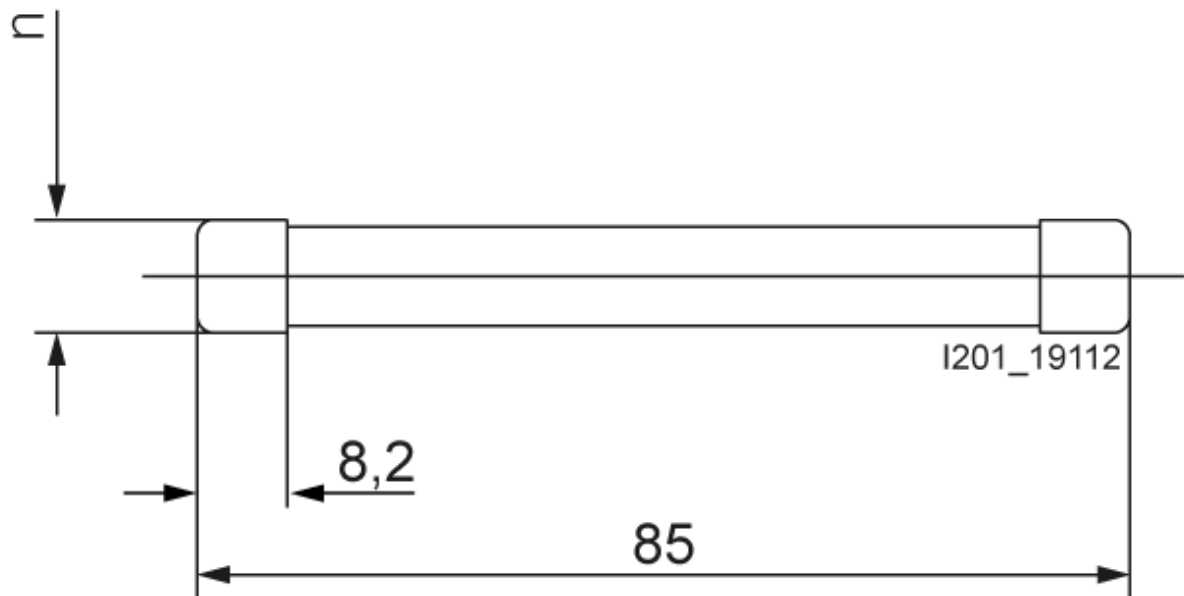

last modified:

4/11/2025 

