

[FEMALE/FEMALE](#) > 0155




0155

DOUBLE FEMALE SLEEVE, BSP PARALLEL THREAD

0155

maximum working pressure	bar	MPa	psi
	250	25,0	3626
working temperature	°C (Celsius)	F (Fahrenheit)	K (Kelvin)
	From -40 to 100	From -40 to 212	From 233 to 373
body	brass		

[FEMALE/FEMALE](#) > 0155

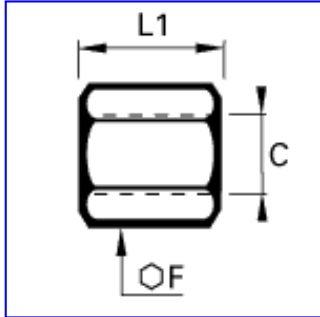

0155
DOUBLE FEMALE SLEEVE, BSP PARALLEL
THREAD

0155

Part No	C	F (mm)	L (mm)	(kg)
0155 10 10	G1/8	14,0	17,0	0,014
0155 13 13	G1/4	17,0	24,0	0,025
0155 17 17	G3/8	22,0	25,0	0,045
0155 21 21	G1/2	27,0	32,0	0,084
0155 27 27	G3/4	32,0	35,0	0,109