

# FiberTuf™

## 76501

light mechanical protection and good grip for dry applications.



Multi Purpose



Light Duty

- Made from aromatic polyester fibre, the Ansell FiberTuf 76-501 Light Mechanical Work Gloves are ideal for providing hand protection when performing dry applications that require light mechanical protection.
- They feature PVC dots on the palm side for improved gripping, and are available in a range of sizes to ensure the most comfortable and secure fit.
- Offers higher performance and durability than traditional cotton and polyamide gloves.



#### Industries

- Construction
- Transportation
- Automotive
- Machinery and Equipment
- Logistics
- Metal fabrication

#### Applications

- Inspection (picking, checking and marking)
- Packaging
- Light assembly tasks
- General handling
- Assembly of parts
- Assembly of white goods

# FiberTuf™

## 76501


light mechanical protection and good grip for dry applications.

### Key Features

- Aromatic polyester fibre for optimal results in dry applications requiring light mechanical protection
- PVC dots on palm side improve gripping for easier and safer handling
- Washable at 40°C for ongoing hygiene maintenance
- Knitwrist cuff provides easier donning
- Available in a range of sizes for a comfortable fit
- Suitable for a range of applications, from automotive and construction to packaging and general handling
- Can be used either as primary glove or as underglove to protect against cold wherever required

### Performance Standards & Regulatory Compliance

#### REACH Compliant

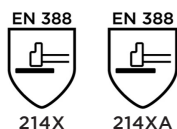

### Specifications

FiberTuf 76-501	<b>Finishing:</b> Dotted on Palm Side <b>Coating Material:</b> PVC <b>Liner Material:</b> Synthetic fiber, Polyester <b>Cuff Style:</b> Knitwrist	13	7, 8, 9, 10	240-270mm	Blue	• 12 pairs/bag, 12 bags/carton
-----------------	--	----	-------------	-----------	------	--------------------------------

For additional information visit us at [www.ansell.com](http://www.ansell.com), or call us at

#### Europe, Middle East & Africa Region

Ansell Healthcare Europe NV  
Riverside Business Park  
Blvd International, 55  
1070 Brussels, Belgium  
T: +32 (0) 2 528 74 00  
F: +32 (0) 2 528 74 01

#### Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.  
Blvd. Bernardo Quintana No. 7001-C,  
Q7001 Torre II,  
Suites 1304, 1305 y 1306,  
Col. Centro Sur, c.p. 76079  
Queretaro, Qro. Mexico  
T: +52 442 248 1544 / 248 3133

#### North America Region

Ansell Healthcare Products LLC  
111 Wood Avenue South,  
Suite 210  
Iselin, NJ 08830, USA  
T: +1 800 800 0444  
F: +1 800 800 0445

#### Canada

Ansell Canada  
105 Lauder  
Cowansville, QC J2K 2K8  
Canada  
T: +1 800 363 8340  
F: +1 800 267 3551

#### Australia

Ansell Limited  
Level 3, 678 Victoria Street,  
Richmond, Vic, 3121  
Australia  
T: +61 1800 337 041  
F: +61 1800 803 578

#### Asia Pacific Region

Ansell Global Trading Center  
(Malaysia) Sdn Bhd  
Prima 6, Prima Avenue  
Block 3512, Jalan Teknokrat 6  
T: +603 8310 6688  
F: +603 8310 6699

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending:  
[www.ansell.com/patentmarking](http://www.ansell.com/patentmarking) © 2021 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.

