

SIVACON, base, with cutouts for flanges, IPXX, T: 800 mm, W: 400 mm, zinc-plated

Model			
product brand name		SIVACON	
design of the product		With cut-outs for flanges	
design of the surface		zinc plated	
design of the product EMC version		No	
material		steel	
protection class IP		IPXX	
product component			
• ventilation		No	
Mechanical Design			
width		400 mm	
depth		800 mm	
net weight		3 900 g	
Approvals Certificates			
General Product Approval		Test Certificates	other




[Special Test Certificate](#)

[Miscellaneous](#)

[Confirmation](#)

other	Environment
Miscellaneous	 Environmental Confirmations

Further information
Information on the packaging https://support.industry.siemens.com/cs/ww/en/view/109813875 Information- and Downloadcenter (Catalogs, Brochures,...) http://www.siemens.com/lowvoltage/catalogs Industry Mall (Online ordering system) https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1048-2UB52-0 Service&Support (Manuals, Certificates, Characteristics, FAQs,...) https://support.industry.siemens.com/cs/ww/en/ps/8MF1048-2UB52-0 Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...) http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1048-2UB52-0 CAX-Online-Generator http://www.siemens.com/cax Tender specifications http://www.siemens.com/specifications

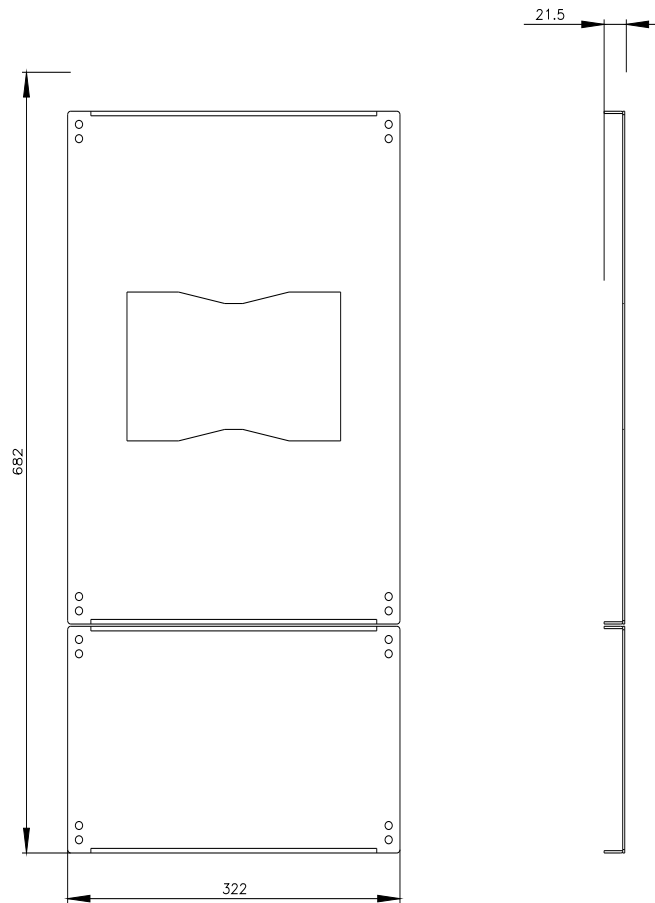

last modified:

6/3/2024 

