




# Datasheet

## RS PRO DC FAN 50x10mm

Stock Number: 789-7867

EN

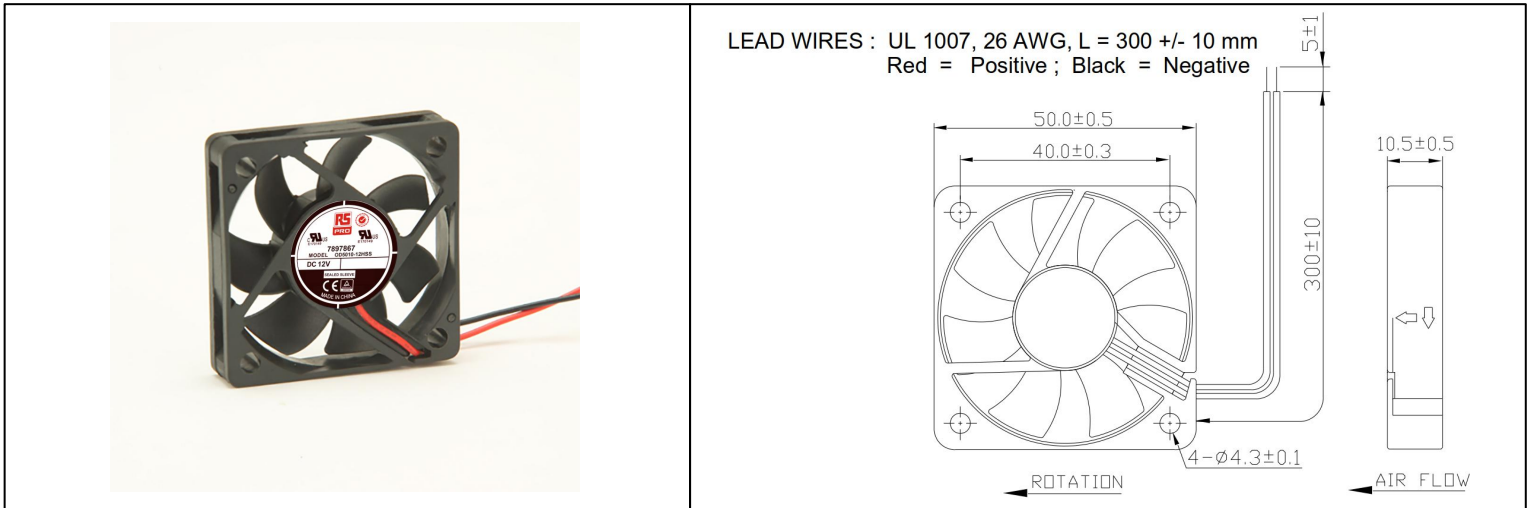

Frame	PBT UL94 V-0 Plastic	<u>Operating Temperature</u> -10°C ~ +70°C	
Impeller	PBT UL94 V-0 Plastic	<u>Storage Temperature</u> -40°C ~ +70°C	
Connection	2x Wire Leads, 26 AWG	<u>Life Expectancy</u> 50,000 hours (L10 at 25°C)	
Motor	Brushless DC, Auto Cutoff, Auto Restart, Polarity Protected	Weight: 0.018Kgs (0.04 lbs)	
Bearing System	Sealed Sleeve		
Dielectric Strength	500VAC/min < 1mA		
Insulation Resistance	10M ohm between leadwire and frame (500VDC)		

Model Number	789-7867
Rated Voltage	12 VDC
Voltage Range	10.8 ~ 13.2
Rated Current	0.15 A
Rated Speed (RPM)	5000
Airflow (CFM)	10.3
Noise Level (dB)	30.4
Max. Static Pressure	0.10" H <sub>2</sub> O