


Features

- Type K Temperature Handle Probe.
- 2m Fully Extended Retractable Curly Thermocouple Lead - Polyurethane outer.
- IEC colour coded.
- The International Electrotechnical Commission (IEC) is an international standards organisation that prepares and publishes international standards.

RS PRO Thermocouple Moving Air Probe - Type K IEC

RS Stock No.: 174-1678

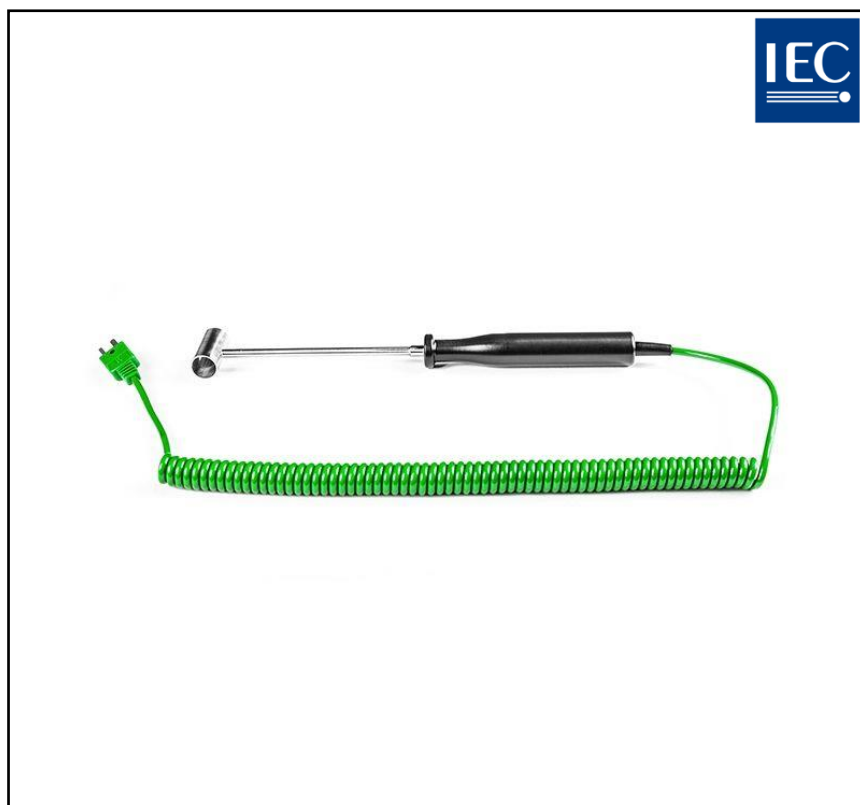

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

Type K Temperature Handle Probe with 2 metres retractable curly lead, terminating in a miniature plug.

General Specifications

General Description	Stainless steel sheath with a moulded handle and 2 metres of coiled extension cable terminated in a miniature thermocouple plug. Thermocouple air probes are ideal for measuring the temperature of still or moving air and gases.
---------------------	--

Mechanical Specifications

Colour Code	K IEC
Sensor Type	Moving Air Probe Type K IEC
Thermocouple Type	K
Probe Tip Type	Funnelled shield Tip
Probe Diameter	30mm Head
Probe Length	120mm
Cable Length	2m Fully Extended
Cable Type	Retractable Curly Thermocouple Lead - Polyurethane outer
Termination	Miniature Plug
Maximum Temperature Measurement	250°C

Approvals

RoHS Compliant	Yes
Standards Met	IEC