

SPECIFICATION

MATERIAL

Insulator: PBT Rated UL94V-0

Contacts: Brass

CONTACT PLATING

Underplate: 50μ" Nickel

Contact Area: 1μ"~30μ" Selective Gold

ELECTRICAL




Current Rating: 1 Amp

Contact Resistance: 30 mΩ Max.

Insulation Resistance: 3000 MΩ Min.

Dielectric Withstanding Voltage: 500 V AC For 1 Minute

Operating Temperature: -40°C To +105°C

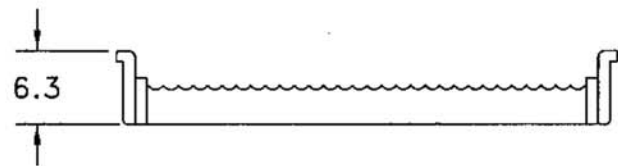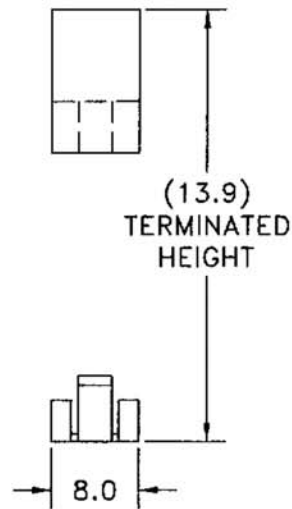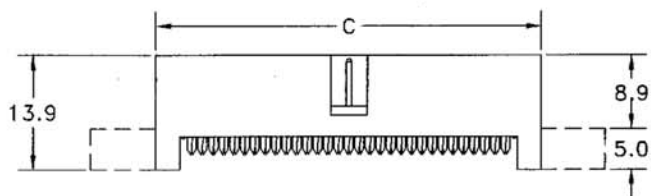

POSITION	A	B	C	D	E
10	36.96	28.60	21.42	18.30	10.16
14	42.04	33.68	26.50	23.38	15.24
16	44.58	36.22	29.04	25.92	17.78
20	49.66	41.30	34.12	31.00	22.86
24	54.74	46.38	39.20	36.08	27.94
26	57.28	48.92	41.74	38.62	30.48
30	62.36	54.00	46.82	43.70	35.56
34	67.44	59.08	51.90	48.78	40.64
40	75.06	66.70	59.52	56.40	48.26
50	87.76	79.40	72.22	69.10	60.96
60	100.46	92.10	84.92	81.80	73.66
64	105.54	97.18	90.00	86.88	78.74

RoHS
Compliant

ITEM NO
AWHCXX-0111-T-R

TITLE
IDC-Low profile header, pitch 2.54 x 2.54mm

ASSMANN
Electronics, Inc.

1840 W. Drake Drive, Suite 101 - Tempe, AZ 85283
Toll Free: 1-877-277-6266 Email: info@usa-assmann.com

THIS DRAWING IS UNPUBLISHED
© Copyright 2008 by Assmann Electronic Components
All International Rights Reserved