


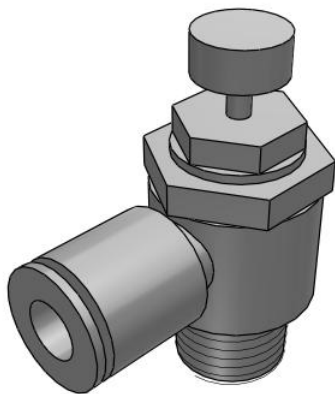

Elbow - AS*2*1F AS2211F-N02-07

Datasheet


General series information

- Port Size: M3, M5, 10-32 UNF, 1/8, 1/4, 3/8, 1/2
- Applicable Tubing O.D.: Ø 2 to Ø 12 mm and Ø 1/8" to Ø 1/2"
- Operating Pressure Range: 0.1 to 1 MPa.

Standard specifications

Size	2 (1/8, 1/4 Basis)
Style	2 (Elbow)
Control Method	1 (Meter-in)
Thread	N (NPT)
Port Size	02 (1/4)
Tube Size	07 (1/4")
Option	None
Fixed Orifice	None
Made to Order	None
Lock Nut	Standard (Hexagon)
Weight	0.030 Kg

Dimensions

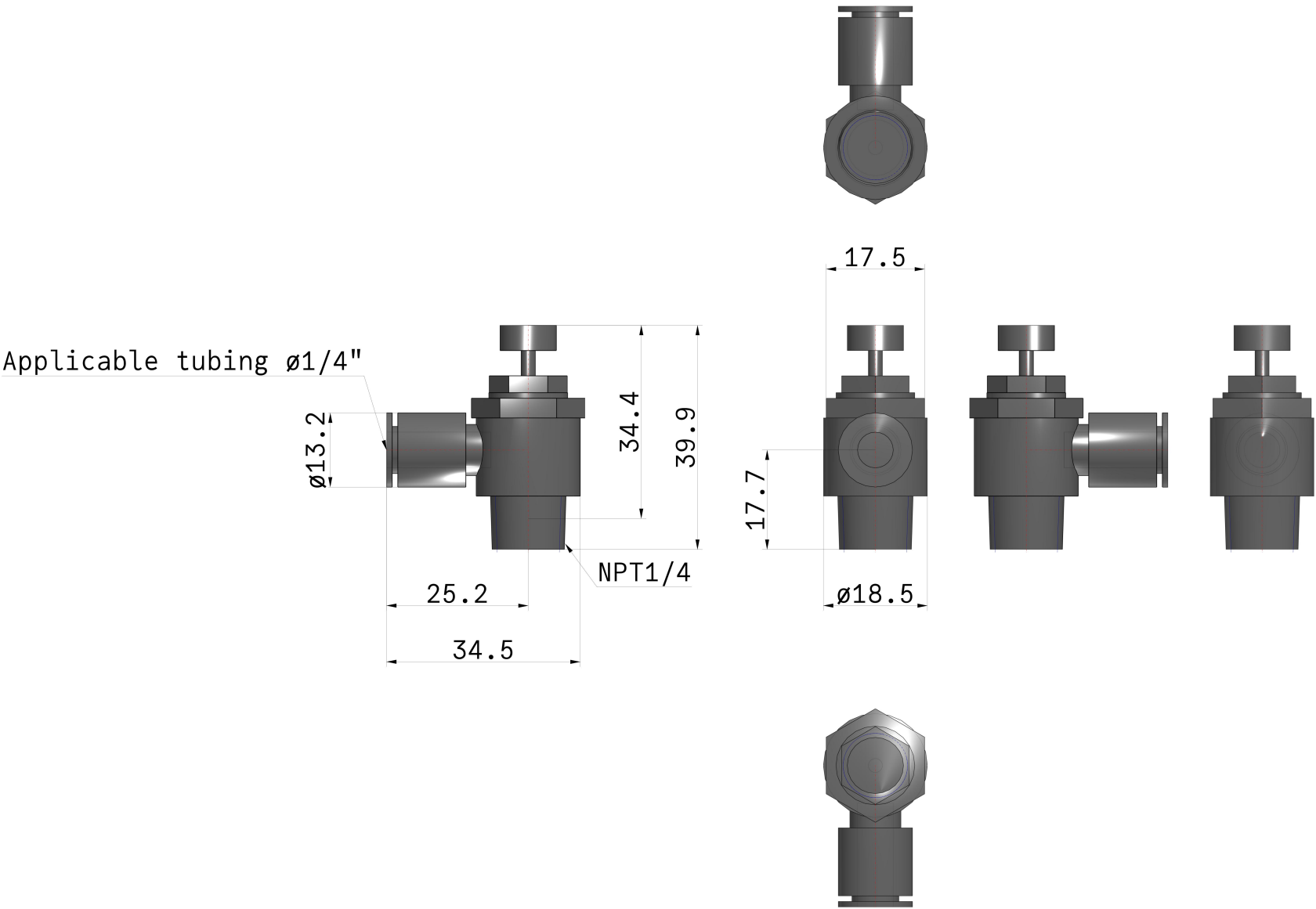

Additional information

Catalogue	AS_2-3_1F-A_EU.pdf
Operation manuals	OM_ASx2x1F_OMG0107EN-B.pdf