

Material:

back part: brass, nickel plated
coupler body: brass, nickel plated
sleeve: brass, nickel plated
valve: brass

springs and
circlip: stainless steel
balls: stainless steel
AISI 420

seals: Buna N
plug: brass, nickel plated

Temperature range:

-20°C to +100°C
(-40°F to +250°F)

Working pressure:

 
0-35 bar
(0-500 psi)

Standard version:

M P N
Nickel plating
Buna N
brass

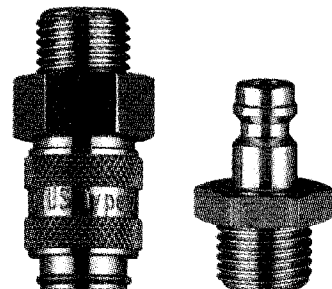
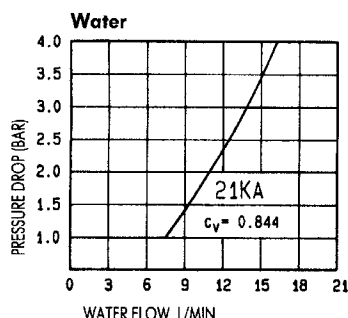
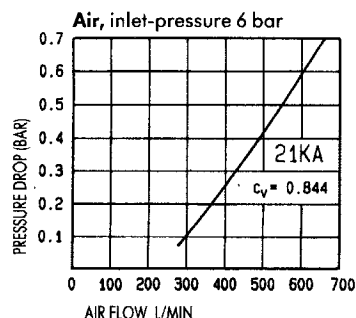
Options:

C = chrome plated
D = durnicoat
V = Viton seals
E = Ethylene
Propylene seals
Other seals on
request
KF = straight through
version
KB = double shut off
R = stainless steel
AISI 303
E = stainless steel
AISI316TI

**Miniature Push-Type**

single shut off

FLOW RATE: 560 l/min

Diagram

Description: Series 21 is ideal for small air tools, dental equipment and automation. Despite its small outer diameter, it has a high capacity with low pressure drop — thus providing significant increases in productivity, efficiency and energy savings. One hand operated. Available in single and double shut-off-coupling.

 
Advantages: High air flow with small external diameter, compact construction, numerous connection variations, manifold applications.

Ideally suitable for: Medical, dental, air tools, robotics, laboratories, emission testing, breathing air, cooling lines.

Interchangeability: RECTUS 90, Camozzi, Schrader Mini.

 
Series 21 - Couplings

Ref. No.	Connection	HEX A/F	Length	Dia.	Price £
<i>Male Thread, BSP Parallel</i>					
21KA AW10 MPN	1/8" BSPP	14	36	16	£3.77
21KA AW13 MPN	1/4" BSPP	17	38	16	£3.77
21KA AW17 MPN	3/8" BSPP	19	38	16	£5.35
<i>Female Thread, BSP Parallel</i>					
21KA IW10 MPN	1/8" BSP	14	36	16	£4.02
21KA IW13 MPN	1/4" BSP	17	38	16	£4.02
21KA IW17 MPN	3/8" BSP	19	38	16	£5.39
<i>Hose Tail</i>					
21KA TF04 MPN	4mm	14	46	16	£4.32
21KA TF06 MPN	6mm (1/4")	14	46	16	£4.03
21KA TF08 MPN	8mm (5/16")	14	46	16	£4.43
21KA TF09 MPN	9mm	14	46	16	£4.16
21KA TF10 MPN	10mm (3/8")	14	46	16	£4.46
<i>Quick Fit Tube Connection</i>					
21KA KO06 MPN	4 x 6mm	14	41	16	£4.10
21KA KO08 MPN	6 x 8mm	14	41	16	£4.10
<i>Panel Mount, Quick Fit Tube Connection</i>					
21KA KS06 MPN	4 x 6mm	14	53	16	£6.77
21KA KS08 MPN	6 x 8mm	17	53	16	£6.77





Series 21 - Couplings (continued)					
Ref. No.	Connection	HEX A/F	Length	Dia.	Price £
Panel Mount, BSP Parallel					
21KA AS10 MPN	1/8" BSP	14	43	16	£5.22
21KA AS13 MPN	1/4" BSP	17	43	16	£5.22
Panel Mount, Standard Hose Tail					
21KA TS04 MPN	4mm	14	60	16	£8.30
21KA TS05 MPN	5mm	14	60	16	£7.94
21KA TS06 MPN	6mm (1/4")	17	60	16	£7.94
21KA TS08 MPN	8mm (5/16")	17	60	16	£8.30
Quick Fit Tube Connection with Spring Guard					
21KA KK06 MPN	4 x 6mm	14	125	16	£6.08
21KA KK08 MPN	6 x 8mm	14	130	16	£6.08
Viton or E.P. Seals				List +	£2.01



Series 21 - Plugs				
Ref. No.	Connection	HEX A/F	Length	Price £
Hose Tail				
21SF TF04 MXN	4mm		32	£0.78
21SF TF05 MXN	5mm		32	£0.78
21SF TF06 MXN	6mm (1/4")		32	£0.67
21SF TF08 MXN	8mm (5/16")		32	£0.78
21SF TF09 MXN	9mm		33	£0.70
21SF TF10 MXN	10mm (3/8")		33	£0.79
Male Thread, BSP Parallel				
21SF AW10 MXN	1/8" BSPP	14	25	£0.79
21SF AW13 MXN	1/4" BSPP	17	28	£0.79
21SF AW17 MXN	3/8" BSPP	19	28	£1.37
Female Thread, BSP Parallel				
21SF IW10 MXN	1/8" BSP	14	25	£0.83
21SF IW13 MXN	1/4" BSP	17	26	£0.83
21SF IW17 MXN	3/8" BSP	19	27	£1.45
Quick Fit Tube Connection				
21SF K006 MXN	4 x 6mm		32	£1.06
21SF K008 MXN	6 x 8mm		32	£1.06
Panel Mount, Quick Fit Tube Connection				
21SF KS06 MXN	4 x 6mm	14	44	£3.42
21SF KS08 MXN	6 x 8mm	17	44	£3.42
Panel Mount, Standard Hose Tail				
21SF TS04 MXN	4mm	14	50	£3.30
21SF TS05 MXN	5mm	14	50	£3.30
21SF TS06 MXN	6mm (1/4")	14	50	£3.30
21SF TS08 MXN	8mm (5/16")	14	50	£3.30
21SF TS09 MXN	9mm	14	50	£3.30
21SF TS10 MXN	10mm (3/8")	17	50	£3.40
Quick Fit Tube Connection with Spring Guard				
21SF KK06 MXN	4 x 6mm		115	£2.54
21SF KK08 MXN	6 x 8mm		120	£2.54

go with the flow

SERIES 21 - PLUGS AND HOSE TAIL COUPLINGS