




Oven GY6.35 12V 50W Clear T300°C

Article number: 145659

BAI Oven GY6.35 11x33mm 12V 50W 850lm Clear T300°C 1000h Ovenlamp

Reliable heat-resistant light bulb which is suitable for use in baking ovens where the temperature can reach up to 300°C. Average life time of 1000h.

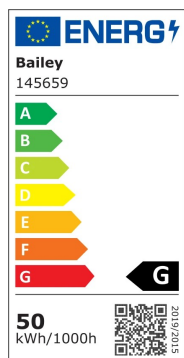

General ETIM properties

ETIM group	Lamps
ETIM class	Low voltage halogen lamp without reflector
Name	Oven GY6.35 12V 50W Clear T300°C
Brand	Bailey
Productseries	Special application
Producttype	OVEN GY6.35

ETIM specifications

Socket	GY6.35
Lamp voltage [V]	12 - 12
Lamp power [W]	50
Diameter [mm]	11
Total length [mm]	33
Suitable for baking oven	Yes
Luminous flux [lm]	850
Colour temperature [K]	2700
Lamp designation	Other
Axial filament	No
Low-pressure technique	Yes
Infrared coating/-technique	No
UV protection	No
Model	Clear
Nominal current [mA]	4167
Xenon	No
Weighted energy consumption in 1000 hours [kWh]	50
Average nominal lifetime [h]	1000
Energy efficiency class according to EU regulation 2019/2015	G