



E·A·R™
Hearing Protection

3M™ E-A-R™ Flexible Fit HA Earplug

Hearing protection simplified.

Introducing the 3M™ E-A-R™ Flexible Fit HA Earplug - the first fully washable foam earplug and the first earplug with an attenuation rating for a new one-hand insertion method.


Breakthrough innovations in hearing protection don't happen every day. That's why we're excited to introduce the 3M™ E-A-R™ Flexible Fit Earplug.

It's the first washable foam earplug that offers two distinctive attenuation ratings, dependent on one-hand or two-hand fitting method with SNR 30 dB and 35 dB respectively.*



First washable foam.

The 3M™ E-A-R™ Flexible Fit Earplug has a patented foam formulation which makes the earplug fully washable and reusable for up to two weeks. The soft foam tip and flexible foam-covered fitting stem allows easy insertion into the ear canal using one or two hands.

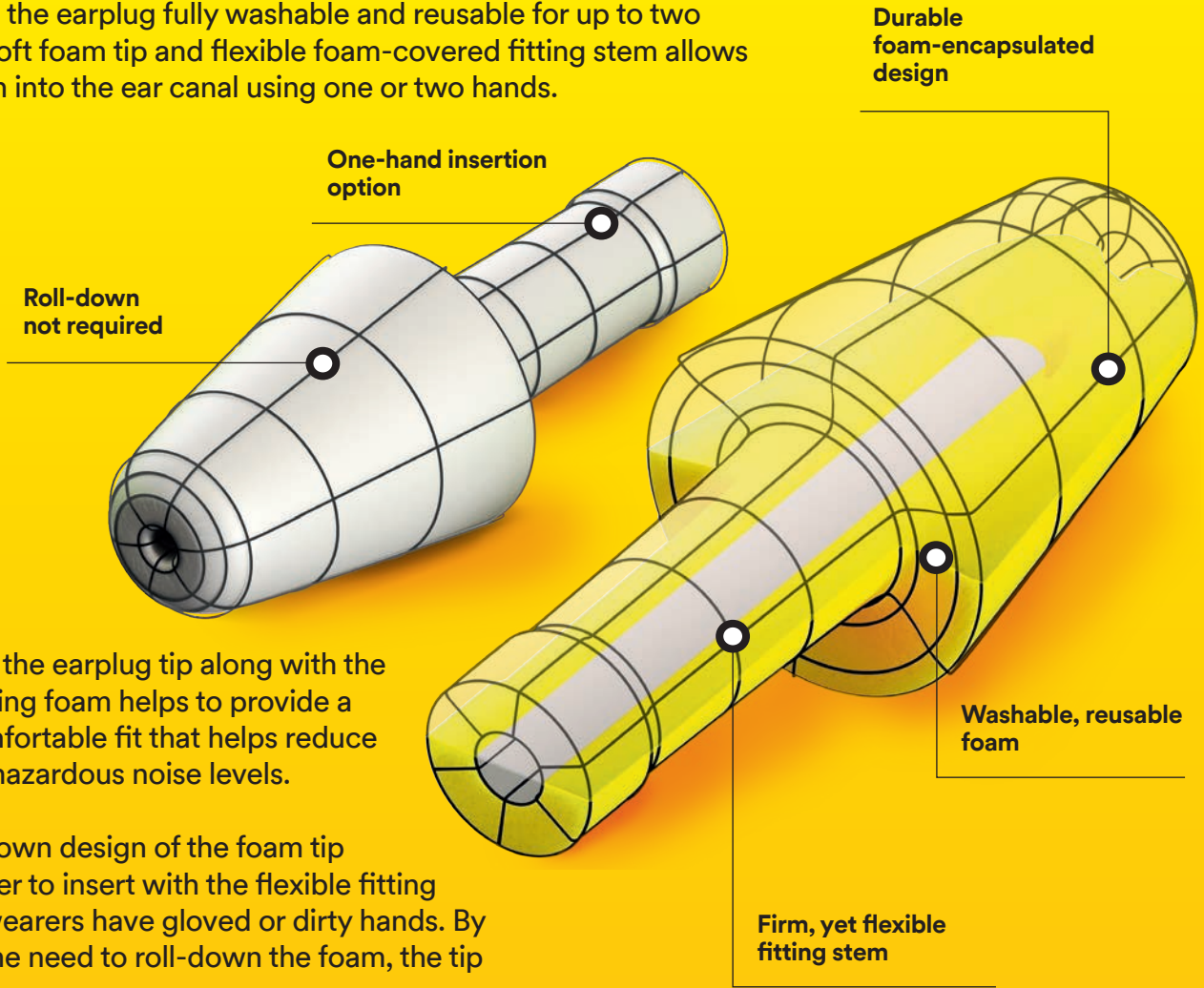

The shape of the earplug tip along with the soft conforming foam helps to provide a snug yet comfortable fit that helps reduce exposure to hazardous noise levels.

The no roll-down design of the foam tip makes it easier to insert with the flexible fitting stem when wearers have gloved or dirty hands. By eliminating the need to roll-down the foam, the tip remains clean.

3M™ E-A-R™ Flexible Fit Earplugs are fit-testable with the 3M™ E-A-Rfit™ Dual-Ear Validation System.*

Product I.D.	3M I.D.	SAP I.D.	Description	
328-1000	70-0717-3228-6	7100212747	3M™ E-A-R™ Flexible Fit Earplug HA 328-1000, CE approved, uncorded, pillow pack, 400 pair per case	
328-1001	70-0717-3229-4	7100212752	3M™ E-A-R™ Flexible Fit Earplug HA 328-1001, CE approved, corded, pillow pack, 500 pair per case	
393-2026-50	70-0717-3269-0	7100216953	3M™ E-A-R™ Flexible Fit Probed Test Plugs, 393-2026-50, 50 pair per case	