

936126-1 ✓ ACTIVE

## MQS


TE Internal #: 936126-1

12 V, 14 Position, Automotive Housing for Male Terminals, Wire-to-Wire, 2.54 mm [.1 in] Centerline, Black, Wire & Cable, Signal

[View on TE.com >](#)



Automotive Parts > Automotive Connectors > Automotive Housings > MQS 0.63mm Unsealed Connectors

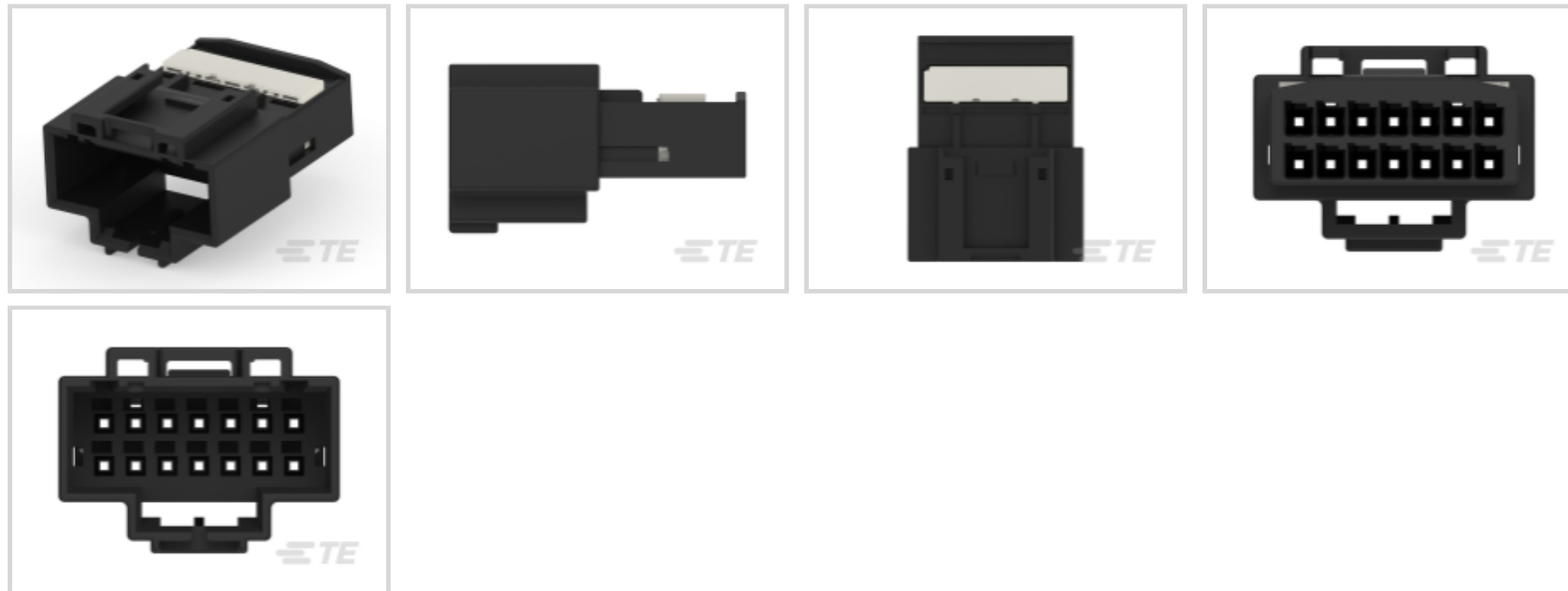

Nominal Voltage Architecture: 12 V

Connector & Housing Type: **Housing for Male Terminals**

Number of Positions: **14**

Sealable: **No**

Number of Rows: **2**

[All MQS 0.63mm Unsealed Connectors \(140\)](#)

## Features

### Product Type Features

Mixed & Hybrid Connector	No
Connector Shape	Rectangular
Connector & Housing Type	Housing for Male Terminals
Sealable	No
Primary Locking Feature	Integrated in Housing
Connector System	Wire-to-Wire
Connector & Contact Terminates To	Wire & Cable

### Configuration Features

Number of Positions	14
Number of Rows	2

### Electrical Characteristics

Operating Voltage	12 VDC
Nominal Voltage Architecture	12 V



### Body Features

Cable Exit Angle	180 °
Primary Product Color	Black

### Contact Features

Contact Size	.63mm
Contact Type	Tab
Mating Tab Width	.63 mm[.02 in]

### Mechanical Attachment

Strain Relief	Without
Terminal Position Assurance	No
Mating Alignment Type	Keyed
Mating Alignment	With
Connector Mounting Type	Cable Mount (Free-Hanging)

### Housing Features

Housing Material	PBT GF15
Centerline (Pitch)	2.54 mm[.1 in]

### Dimensions

Row-to-Row Spacing	3.4 mm[.133 in]
Product Width	22.6 mm[.89 in]
Product Length	29 mm[1.14 in]
Connector Height	16.5 mm[.65 in]

### Operation/Application

Circuit Application	Signal
---------------------	--------

### Packaging Features

Packaging Quantity	200
Packaging Method	Tray

### Other

Serviceable	No
Connector Position Assurance Capable	No

### Product Compliance

 
[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	有害物质含量符合标准要求 No Restricted Substance(s) Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2025 (250) Candidate List Declared Against: JUNE 2025 (250) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability


#### Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

## Compatible Parts



## Customers Also Bought

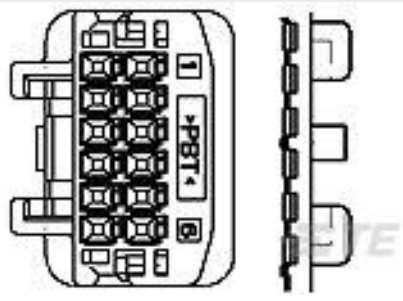

TE Part #1473413-1  
025 G 24POS CAP ASSY W TO W



TE Part #1-2177909-2  
MCON 0.5 CB, CONTACT



TE Part #2278701-1  
12POS, TAB1.0X0.6, HDR ASSY, 180DEG



TE Part #2278770-1  
4P SOCKET HOUSING



TE Part #2334366-1  
32POS, HYBRID, HDR ASSY, 90DEG, SLDR



TE Part #6-2278526-1  
10POS, AMP MCP1.5K, REC HSG, ASSY



TE Part #2359790-1  
67POS, HYBRID, HDR ASSY, 90DEG, SLDR

TE Part #2400451-1  
SCR403 Resolver Rotor



TE Part #2405580-1  
12POS, MCON 0.5, REC HSG, UNSLD, COD A

TE Part #2477340-1  
CEV40 HEADER CABLE ASSY, HYCET

## Documents

### Product Drawings

#### 14POS MQS TAB

English

### CAD Files

#### Customer View Model

[ENG\\_CVM\\_CVM\\_936126-1\\_A.2d\\_dxf.zip](#)

English

#### Customer View Model

[ENG\\_CVM\\_CVM\\_936126-1\\_A.3d\\_igs.zip](#)

English

### 3D PDF

3D

#### Customer View Model

[ENG\\_CVM\\_CVM\\_936126-1\\_A.3d\\_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

## Product Specifications

936126-1

12 V, 14 Position, Automotive Housing for Male Terminals, Wire-to-Wire, 2.54 mm [.1 in] Centerline, Black, Wire & Cable, Signal



## Product Specification

English