

15

1532 07


 
 
Jack connectors



Jack plug insert acc. to JIS C 6560 JC35P3, 3.5 mm, 3 poles/
stereo, straight version, with solder terminals

15

1532 07

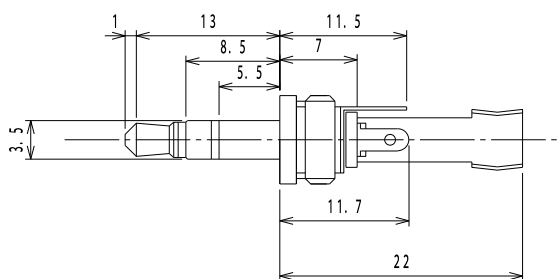

Environmental conditions

Temperature range -20 °C/+70 °C

Materials

Insulating body PC, HB according to UL94
Contact CuZn/steel, nickel-plated
Insulation POM, HB according to UL94

Electrical data (at T_{amb} 20 °C)

Rated current 1 A
Rated voltage 34 V AC/DC
Rated impulse voltage 500 V/60 s
Insulation resistance $\geq 100 \text{ M}\Omega$

Associated products

Counterparts

☞ 1502 01	☞ 1502 06	☞ 1502 07
☞ 1502 08	☞ 1503 02	☞ 1503 03
☞ 1503 08	☞ 1503 09	☞ 1503 17
☞ 1503 18	☞ 1503 27	☞ 1503 29
☞ 1503 30	☞ 1520 01	☞ 1520 02
☞ 4510	☞ 4511	☞ KLB 4
☞ KLBR 4		

15

1532 07

Designation	Pole Number	PU (Pieces)	MDQ (Pieces)
1532 07	3	100	500

Packaging:

in bulk, in a cardboard box or a plastic bag