


## FEATURES

- **Heat Stabilised Material:** Suitable for high-temperature environments up to 105 °C
- **Nylon Construction:** Provides durability and resistance to wear
- **Length of 100 mm:** Ideal for bundling smaller cables and wires
- **Maximum Bundle Diameter of 22 mm:** Accommodates a variety of cable sizes
- **Tensile Strength of 8 kg:** Ensures secure fastening
- **UL 94 V-2 Fire Behaviour:** Offers flame retardancy for enhanced safety
- **Light Green Colour:** Allows for easy identification and organisation

## RS PRO Heat Stabilised Cable Tie, 100 mm Nylon

RS Stock No: 656-015

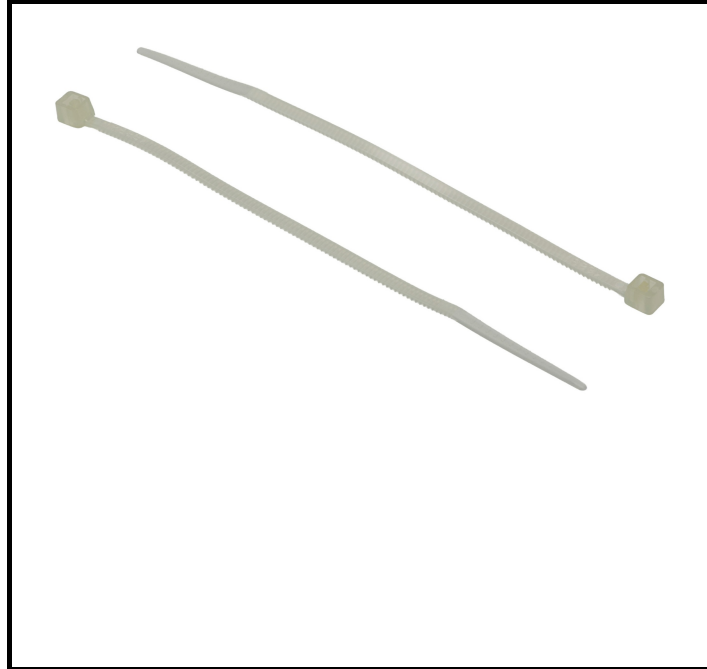

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

### Product Description

The RS PRO heat stabilised cable tie is designed for secure and reliable bundling of cables and wires. Made from durable nylon, it offers excellent tensile strength and is ideal for use in environments with elevated temperatures. Its light green colour provides easy identification and organisation.

### General Specifications

Colour	Light Green
Product Type	Cable Tie
Sub Type	Heat Stabilised
Tensile Strength	8 kg

### Protection Category

Fire Behaviour	UL 94 V-2
UV Resistant	No

### Mechanical Specifications

Length	100 mm
Material	Nylon
Maximum Bundle Diameter	22 mm
Width	2.5 mm

### Operation Environment Specifications

Maximum Operating Temperature	105 °C
-------------------------------	--------

### Approvals

Standards/Approvals	ABS 15-TA1338482-PDA, cULus E97527, RoHS, UL94V-2
---------------------	---

