




LED FIL Mini Candle C22 GS1 E14 1W (12W) 100lm 827 Frosted

Article number: 147112

BAI LED Filament Candle Mini C22 GS1 E14 22x88mm 1W 2700K Frosted 100lm (12W) 230V-240V 320° LED-lamp

This LED filament bulb is the energy-saving evolution of the traditional incandescent lamp. The advanced filaments replace the old-fashioned wire, offering a warm glow while consuming significantly less power and lasting much longer. With its frosted glass and elegant tip, this candle bulb is perfect for classic chandeliers, wall sconces, and decorative fixtures. A timeless look with a sustainable twist.

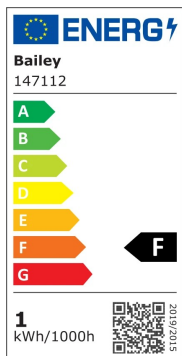

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED FIL Mini Candle C22 GS1 E14 1W (12W) 100lm 827 Frosted
Brand	Bailey
Productseries	LED Filament candle
Producttype	C22 E14 827 FR

ETIM specifications

Socket	E14
Luminous flux [lm]	100 - 100
Nominal voltage [V]	220 - 240
Lamp power [W]	1 - 1
Colour temperature [K]	2700 - 2700
Diameter [mm]	22
Length [mm]	88
Dimmable	No
Lamp shape	Candle
Beam angle [°]	320 - 320
Colour	White
Type of glass/cover	Frosted
Lamp designation	Other
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	Yes
Rated luminous flux according to IEC 62612 [lm]	100
Power factor	0.9
Lamp efficacy [lm/W]	100
Nominal current [mA]	9 - 9
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	Colourless
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	1
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	F
With twilight switch	No
Material of light bulb	Glass