



S-TEX 377SC

CUT PROTECTION WITH GAUNTLET SAFETY CUFF

Double-dipped, fully coated nitrile with extra nitrile foam coating on palm over Hagane Coil® liner (stainless steel/polyester), and PVC/polyester safety cuff. Safety cuff provides protection over the wrist as well as easy donning and doffing.

FEATURES

- › Cut resistant: Level D (EN 388:2016)
- › 13 gauge knitted liner, engineered with Hagane Coil® technology
- › Strong, sturdy cuff extends protection to over this wrist
- › Safety cuff enables quick and easy removal in case of emergency
- › Nitrile coating with a second foamed nitrile coating provides high abrasion resistance
- › Protects the hand from oils, hydrocarbons, grease and abrasion, with long lasting grip performance under wet and oily conditions
- › An ergonomically designed hand mould replicates the natural curvature of the human hand to reduce hand fatigue, increasing productivity and dexterity
- › Seamless knitting gives no irritation
- › Liquid-proof to end of coated area
- › Optimal grip performance in wet & oily conditions



SHOWA **HAGANE**
COIL® TECHNOLOGY



SUITABLE FOR


Typical Industries

- Agriculture
- Construction
- Glass
- Mining
- Oil and Gas

Suitable Applications

- Drainage
- Glass and window handling
- Plumbing
- Steel erecting
- Bottling
- Heavy equipment handling

CERTIFICATION

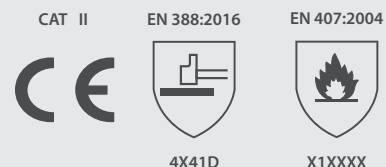

See overleaf for explanation



S-TEX 377SC

SUITABLE FOR

MATERIALS	LINER:	Hagane Coil® (Stainless Steel/Polyester)
	COATING:	Nitrile with Foam Nitrile Palm / PVC/ Polyester safety cuff
COLOUR	Black/Blue	
LENGTH (mm)	290-320	
CUFF STYLE	Gauntlet	

RECOMMENDATIONS FOR USE

- Do not use where there are chemical, electrical, thermal (more than 100°C) or entanglement risks.
- Wash at 40°C max. Performance levels as per
- standard EN388 retained after 3 washes, subject to variations linked to actual usage conditions.
- The performance levels apply to the coated surface only.
- Store in a dry place, away from the light.


ORDERING DETAILS

SIZE	CODE	PACKAGING
7/M	SHOS377C2	5 pairs per bag
8/L	SHOS377C3	60 pairs per case
9/XL	SHOS377C4	
10/XXL	SHOS377C5	

CERTIFICATION LEGENDS




MECHANICAL HAZARDS EN 388:2016 PERFORMANCE LEVELS*

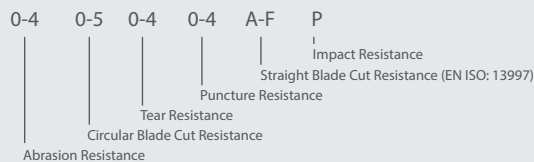

*If tests are not performed or are not applicable, 'X' will be placed instead of a number/letter



HEAT AND FIRE EN 407

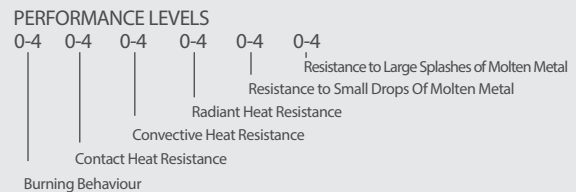

EUROPE

www.globusgroup.com

E: sales@globus.co.uk
T: +44 (0)161 877 4747
F: +44 (0)161 877 4746

MIDDLE EAST AND AFRICA

www.globusgroup.com/gcc

E: gcc@globusgroup.com
T: +971 4 882 9962
F: +971 4 882 9963



Globus Group, T2 Trafford Point, Twining Road, Trafford Park, Manchester, M17 1SH, UNITED KINGDOM
 Globus EMEA FZE, Jafza One, Tower A, Office 2201, Jebel Ali, PO Box 61195, Dubai, UNITED ARAB EMIRATES

© 2019 Globus (Shetland) Ltd | GGR-SHO-DATA-STEX377SC-1119_2