


Data Specification Sheet

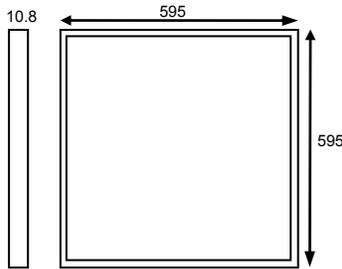

Recessed 600x600 45W Dimmable LED Panel Fittings

Code	851-2911
Description	Recessed 45W Dimmable LED modular fitting
Overall dimensions (mm)	(D)10.8mm (L)595mm (W)595mm
Product weight	4.9kg (c/w Driver)
Wattage	45W
Circuit Watts	45W
Lumen Output & Efficiency	3100Lm – 68Lm/W
Recommended product location	Indoor
Finishes available	Silver – Opal Diffuser
Output Colour	4200K Cool White
Control Gear Type	Remote Constant Current 1400mA Dimmable Driver (Supplied)
Dimmable	Yes
Lamp Supplied	Yes – Non replaceable
Class	Class III.(LED Panel) Class II (Driver)
IP	IP20
Photometric Testing	Yes
Instruction sheet	Yes
Origin of manufacture	China
Main materials:	
• Chassis	Aluminium
• Diffuser	Opal Polycarbonate
Method of fix	Lay-in suitable for 600mm x 600mm recessed exposed 15mm & 25mm T ceilings. Suspension Brackets (Supplied) for use with 2 x 5FTT5KIT (Not supplied)
Lampholder cap and make	N/A – Non replaceable lamps
Electrical Connections	Direct plugin to remote driver
F mark	Yes
CE mark	Yes
Quality Assurance System	Yes ISO 9001 QMS
Batch coding details on product	Yes
Certificate of Conformity (Held on File)	Yes
Manufactured in accordance	EN60 598
Warranty	5 Years