





Visual Signals **XENON** **BEACONS**

Industrial Xenon Beacons > X75 Series

Product overview

The X75 Series utilises a discharge capacitor and converter circuit to ignite xenon gas inside a tube, resulting in a brilliant flash

of light. Xenon gas ignites virtually instantaneously so maximum brightness is obtained immediately. Xenons have an added advantage of low current consumption and are one of the most efficient, effective and brightest visual signals available.

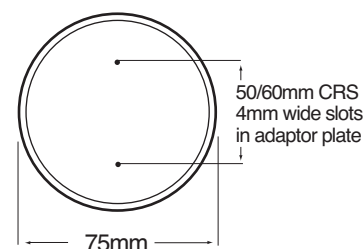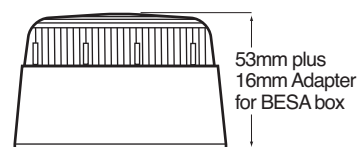

FEATURES

Continuously rated

Suitable for surface or wall mounting

Suitable for use with conduit
BESA box - adaptor supplied

IP65

MATERIAL

UV Stable Polycarbonate Lens
ABS Plastic Base

Code No:	Voltage:	Light Source:	Current:
X75-24	24v Dc ---	Xenon 0.30J	40 mA
X75-115	115v Ac ~	Xenon 1.0J	35 mA
X75-230	230v Ac ~	Xenon 1.0J	20 mA



Kg 0.13

50/60 **Hz**

°C -20+40

IP 65

FPM 60

FIRE

APPROVAL AND
CONFORMITIES



ADD THE FOLLOWING LENS
CODES TO THE PRODUCT
CODE WHEN ORDERING

01

02

03

04

05



INDUSTRIAL