

**AMP** AMP Connect

MAIN MENU HELP  
FAMILIES REGISTRATION

Alphabetical Picture Part Number  
SEARCH SEARCH SEARCH

Go To Step Search™ screen


**141462-1** -- 1 of 1 products

Terminals and Splices  
Miscellaneous Terminals

General **INFO**

Sales **INFO**

Customer Drawings  
**SPECIFICATIONS**

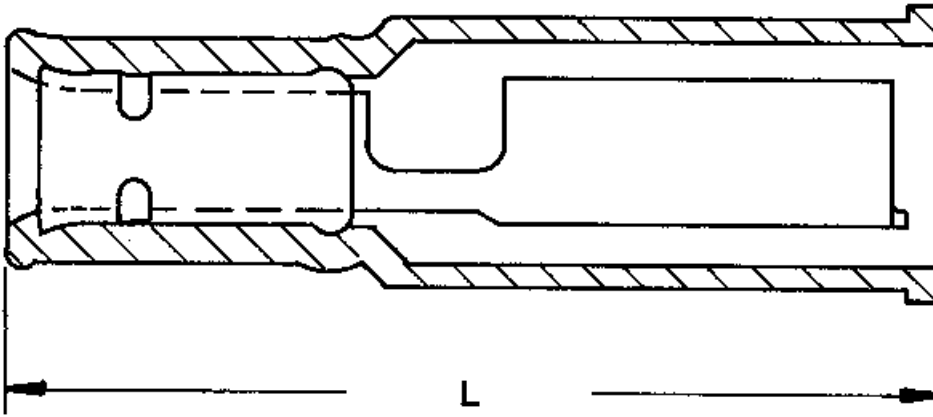

Line art represents typical product only.

### Searchable Features:

Product Type	Shur-Plug
Insulation Support	Insulation Support
Wire Range	[0.50-1.50 <sup>2</sup> ] AWG [mm]
Double Wire	No

### Other Properties:

Dim. L	.945 [24.00] Max. in. [mm]
Receptacle Style	Straight
Insulation	Yes
Insulation Diameter	.130 [3.30] Max. in. [mm]
Insulation Sleeve Material	Copper
Color	Red