


Part Number: [0151660431](#)
Status: Active
Overview: [FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers](#)
Description: 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 102.00mm Cable Length, Tin (Sn) Plating, 40 Circuits

Documents:	
図面 (PDF)	Datasheet (PDF)
製品仕様書 PS-15166-001-001 (PDF)	RoHS Certificate of Compliance (PDF)

一般 コメント	Contacts on the same side, Type A
Crimp Quality Equipment 概要	Yes FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
製品名 UPC	Premo-Flex FFC Jumper 884982849297
機械的性能/材質 ケーブル長 極数 (実装) Contact Layout Type 材質 - 嵌合部メッキ Net Weight 梱包形態 ピッチ - 嵌合部 (インチ) 使用温度範囲 電線サイズ (AWG) ケーブル種別	 102.00mm 40 A (same side) 錫 1.000/g ポリ袋 0.50mm -40° to +105° C N/A FFC
電気的性能 最大定格電流 最大定格電圧	 0.5A 60V AC
参考情報	
図面・仕様書情報 製品仕様書 製品図面	 PS-15166-001-001 SD-15166-001-001

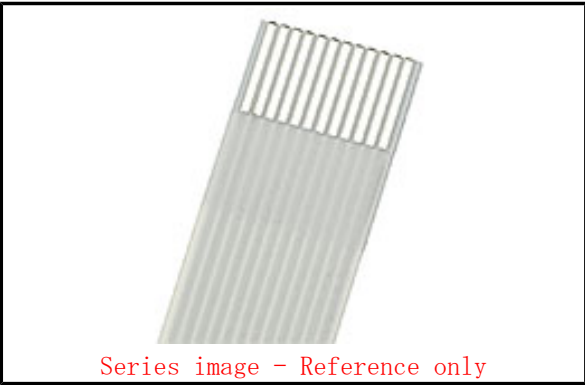

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Contained Per - D(2021)10043-DC (17 Jan 2022) Halogen-Free Status Not Low-Halogen	China RoHS
For more information, please visit Contact US	
China ROHS ELV RoHS Phthalates	Green Image Not Relevant Not Contained

Search Parts in this Series
[15166](#) Series

Mates With
Easy-On FFC/FPC Connector: . [541044033](#)
, [541324033](#) , [5019514000](#) , [525594033](#)