




Datasheet

ENGLISH

Stock No

Planar Cable

4242012
4242034

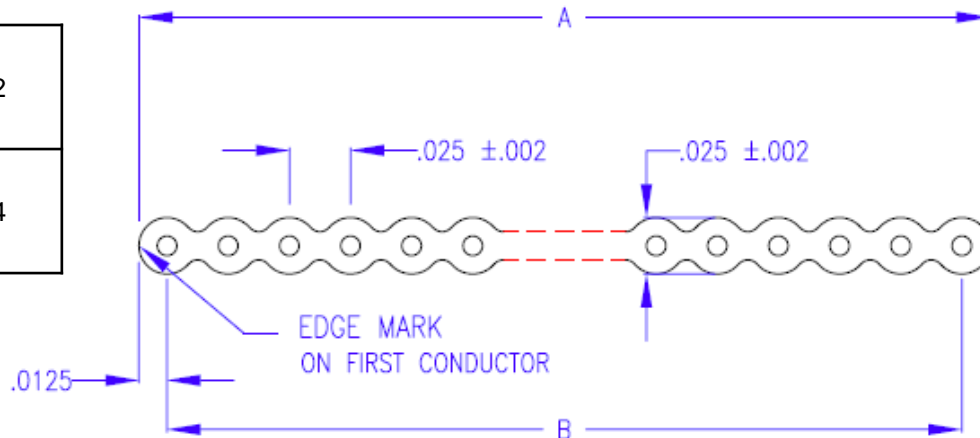

CONDUCTORS	30 AWG solid bare copper
INSULATION	0.0075" PVC, grey with black edge mark
TEMPERATURE RATING	105°C
IMPEDANCE	80 ohms
CAPACITANCE	19 pF/ft @ 1MHz
INDUCTANCE	.15 uH/ft @ 1MHz
PROP DELAY	1.50 ns/ft
DC RESISTANCE	103 ohms/1000 ft Max.

CURRENT RATING	0.9A @ 10°C rise above ambient
VOLTAGE RATING	150 V
INSULATION RES	10 ohms 10ft minimum
APPROVALS	UL AWM style 20130 VW1 CSA AWM FT-1

STOCK NO	NO OF CONDUCTORS	A SPAN"	A SPAN mm	B SPAN"	B SPAN mm
4242012	12	.300 ± 0.011	7.62 ± 0.28	.275 ±.005	6.99 ± 1.3
4242034	34	.850 ± 0.011	21.59 ± 0.28	.825 ±.006	20.96 ± 1.5