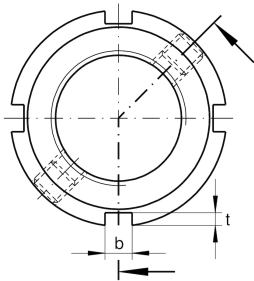
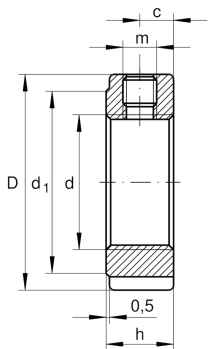
**ZMA75/125** **Precision locknut**

Precision locknuts ZMA, locking pegs, radially arranged, heavy series

Technical information**Main Dimensions & Performance Data**

d	M75X2	Thread
D	125 mm	Outside diameter
h	38 mm	Height
M _A	15 Nm	Mounting torque set screw
F _{aB}	880,000 N	Breaking load, axial
M _L	260 Nm	Breakawag
M _{AL}	150 Nm	Mounting torque reference
M _M	62.2 kg*cm ²	Mass moment of inertia
≈m	2.312 kg	Weight

Dimensions

d ₁	117 mm	Plant diameter outside
t	3.5 mm	Hight retaining slot
b	8 mm	Width retaining slot
c	19 mm	Distance bore
m	M8	Threaded - threaded pin