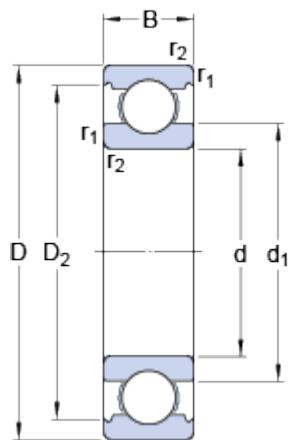
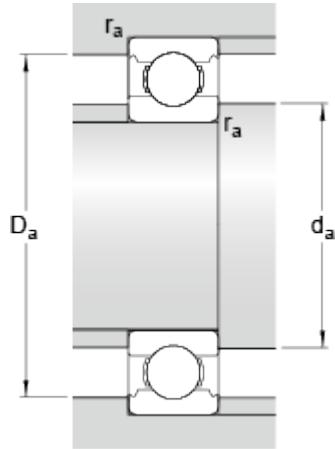


6307

SKF Explorer

Dimensions

d	35	mm
D	80	mm
B	21	mm
d_1	≈ 49.56	mm
D_2	≈ 69.2	mm
$r_{1,2}$ min.	1.5	mm

Abutment dimensions

d_a min.	44	mm
D_a max.	71	mm
r_a max.	1.5	mm

Calculation data

Basic dynamic load rating C	35.1	kN
Basic static load rating C_0	19	kN
Fatigue load limit P_u	0.815	kN
Reference speed	19000	r/min
Limiting speed	12000	r/min
Calculation factor k_r	0.03	
Calculation factor f_0	13.1	

Mass

Mass bearing	0.456	kg
--------------	-------	----