



**FABRIQUE EN
FRANCE**

3 YEARS
MANUFACTURER
GUARANTEE


Product number 1169721200
EAN 3281857212007

TECHNICAL DATA

Cable quality	PVC	Plug system plug	Type E (FR)
Cable length	20 m	Plug system socket	Type E (FR)
Cable designation	H05VV-F 3G1,5	Max. current carrying capacity	16 A
Cable colour	yellow	Degree of protection (IP)	IP20

PACKAGING, DIMENSIONS AND WEIGHTS

UP	1	Weight of product (including packaging)	2.82 kg
Weight of product (without packaging)	2.67 kg	Dimension LxWxH (incl. packing)	25.6 cm x 14.5 cm x 25.5 cm
Dimension LxWxH (without packing)	25 cm x 12 cm x 25 cm		

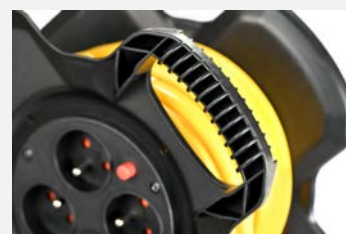

**FABRIQUE EN
FRANCE**

3 YEARS
MANUFACTURER
GUARANTEE



Product number
EAN

1169771150
3281857711500

TECHNICAL DATA

Cable quality	PVC	Max. current carrying capacity	16 A
Cable length	15 m	USB charging units	2
Cable designation	H05VV-F 3G1,5	USB type output socket	Type A
Cable colour	yellow	Max. output current USB	2.1 A
Plug system plug	Type E (FR)	Degree of protection (IP)	IP20
Plug system socket	Type E (FR)		

PACKAGING, DIMENSIONS AND WEIGHTS

UP	1	Weight of product (including packaging)	2.31 kg
Weight of product (without packaging)	2.17 kg	Dimension LxWxH (incl. packing)	26.5 cm x 14.5 cm x 25.5 cm
Dimension LxWxH (without packing)	25 cm x 12 cm x 25 cm		



**FABRIQUE EN
FRANCE**

3 YEARS
MANUFACTURER
GUARANTEE



Product number
EAN

1169711150
3281857111508

TECHNICAL DATA

Cable quality	Rubber-Neoprene
Cable length	15 m
Cable designation	H07RN-F 3G1,5
Cable colour	red

Plug system plug	Type E (FR)
Plug system socket	Type E (FR)
Max. current carrying capacity	16 A
Degree of protection (IP)	IP44

PACKAGING, DIMENSIONS AND WEIGHTS

UP	1
Weight of product (without packaging)	2.82 kg
Dimension LxWxH (without packing)	25 cm x 12 cm x 25 cm

Weight of product (including packaging)	2.91 kg
Dimension LxWxH (incl. packing)	26.5 cm x 14.5 cm x 25.5 cm


**FABRIQUE EN
FRANCE**
3 YEARS
MANUFACTURER
GUARANTEE

Product number
EAN

1169761100
3281857611008

TECHNICAL DATA

Cable quality	Rubber-Neoprene	Max. current carrying capacity	16 A
Cable length	10 m	USB charging units	2
Cable designation	H07RN-F 3G1,5	USB type output socket	Type A
Cable colour	black	Max. output current USB	2.1 A
Plug system plug	Type E (FR)	Degree of protection (IP)	IP44
Plug system socket	Type E (FR)		

PACKAGING, DIMENSIONS AND WEIGHTS

UP	1	Weight of product (including packaging)	2.25 kg
Weight of product (without packaging)	2.1 kg	Dimension LxWxH (incl. packing)	26.5 cm x 14.5 cm x 25.5 cm
Dimension LxWxH (without packing)	25 cm x 12 cm x 25 cm		



**FABRIQUE EN
FRANCE**

3 YEARS
MANUFACTURER
GUARANTEE



Product number
EAN

1169711101
3281857111010

TECHNICAL DATA

Cable quality	Rubber-Neoprene
Cable length	10 m
Cable designation	H07RN-F 3G2,5
Cable colour	red

Plug system plug	Type E (FR)
Plug system socket	Type E (FR)
Max. current carrying capacity	16 A
Degree of protection (IP)	IP44

PACKAGING, DIMENSIONS AND WEIGHTS

UP	1
Weight of product (without packaging)	2.78 kg
Dimension LxWxH (without packing)	25 cm x 12 cm x 25 cm

Weight of product (including packaging)	2.93 kg
Dimension LxWxH (incl. packing)	26.5 cm x 14.5 cm x 25.5 cm