



# ORRA-B

## LED LIGHT BATTEN



- 4000K single colour
- 120° Light distribution
- Up to 120lm/W
- IP65 Ingress protected
- Excellent optical design
- Impact tested to IK08
- Surface and pendant mounting for ease of installation
- Available in single and twin variations: 4ft, 5ft and 6ft
- Emergency versions available

### ORRA-B SPECIFICATION

Part Code	ORRV-B4S25-4K	ORRV-B4T50-4K	ORRV-B5S35-4K
Lumens	3000lm	6000lm	4200lm
Input Voltage	220~240VAC	220~240VAC	220~240VAC
Power	25W	50W	35W
Power Factor	>0.9	>0.9	>0.9
Colour	4000K	4000K	4000K
CRI	>80	>80	>80
Working Temperature	-20°C~45°C	-20°C~45°C	-20°C~45°C
Beam Angle	120°	120°	120°
Dimensions	1267 x 75 x 70mm	1267 x 115 x 70mm	1567 x 75 x 70mm
	Replacement for 1 x 36W	Twin replacement for 2 x 36W	Replacement for 1 x 58W

Part Code	ORRV-B5T70-4K	ORRV-B6S40-4K	ORRV-B6T80-4K
Lumens	8400lm	4800lm	9600lm
Input Voltage	220~240VAC	220~240VAC	220~240VAC
Power	70W	40W	80W
Colour	4000K	4000K	4000K
CRI	>80	>80	>80
Working Temperature	-20°C~45°C	-20°C~45°C	-20°C~45°C
Beam Angle	120°	120°C	120°C
Dimensions	1567 x 115 x 70mm	1867 x 75 x 70mm	1867 x 115 x 70mm
	Twin replacement for 2 x 58W	Replacement for 1 x 70W	Twin replacement for 2 x 70W



### Available Variants

3 hour emergency pack.

ORRV-BXXXX-4K-EM 3Hr Emergency  
 Working Temperature 0°C ~ +30°C

PowerLed (UK) Ltd  
 Orion House  
 Calleva Park  
 Aldermaston  
 Berkshire  
 RG7 8SN

Contact:  
 Tel: 0118 9703856  
 enquiries@powerled.uk.com  
 www.powerled.uk.com



 



# ORRA-B



## LED LIGHT BATTEN

### Mechanical Diagrams

SINGLE

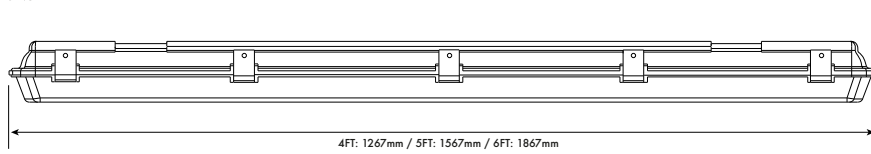

TWIN

 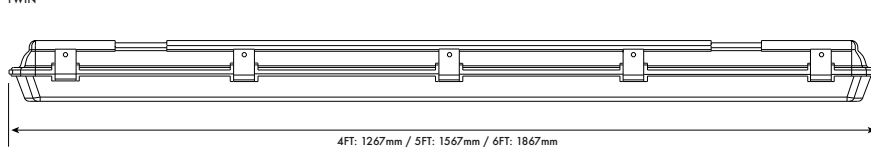

PowerLed (UK) Ltd  
Orion House  
Calleva Park  
Aldermaston  
Berkshire  
RG7 8SN

Contact:  
Tel: 0118 9703856  
enquiries@powerled.uk.com  
www.powerled.uk.com

