

# H65Z Waterproof Cable Connector

- The safe way to repair and extend electric cables on garden appliances and power tool equipment.
- Easy to follow wiring instructions.
- Waterproof for added protection.


## TECHNICAL DATA

3 x 2.5mm<sup>2</sup> 600 volts ac/dc  
Max cable diameter 16.5mm  
Dimensions 32 x 120mm  
Weight 60g

**GUARANTEE**  
Your PowerBreaker  
Cable Connector is  
guaranteed for 12  
months

MADE IN DENMARK

**IMPORTANT – FOR YOUR PROTECTION**  
Electricity is dangerous. Cables and connectors should never be immersed in water. Do not allow children to tamper with electrical devices. Always unplug from mains supply before any inspection or repair to equipment. Disconnect the appliance from the mains before fitting connector.

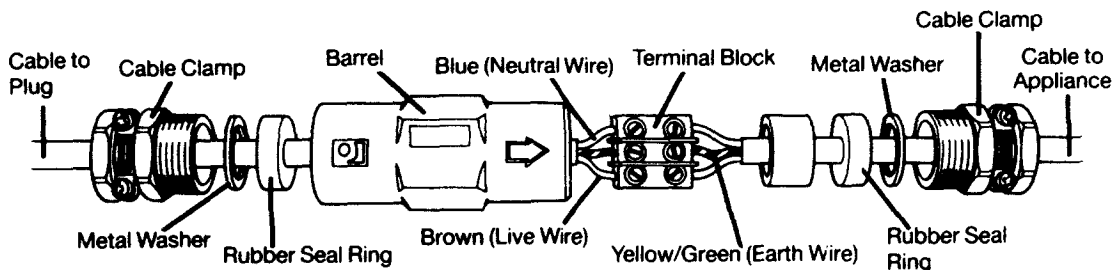

## WIRING INSTRUCTIONS

1. Dismantle the cable connector as shown in the diagram by unscrewing both end cable clamps. The internal components can then be released from inside the barrel by gently tapping on a work surface (check that all parts are present).
2. Thread the cable through the components as shown in the diagram. When threading through the waterproof rubber seal ring, the centre rings will automatically push out and the ring will adjust itself to the circumference of the cable used. Discard the centre rings that fall out.
3. Connect the wires to the terminal block in the direction shown in the diagram making sure that the brown live wire connects to the brown live wire and the same for the earth to the earth and the neutral to the neutral wires.
4. Push all the components back into the barrel and screw in the ends.
5. Tighten the cable clamp screws to secure the cables. Finally please note that these are reversible for different thicknesses of cable.