


KEMET Part Number: EFX6(01)-80X80T0800
(UFSEX6010FT080, EFX6(01)80X80T0800)

KEMET, EFX6, Flex Suppressors, Noise Suppression

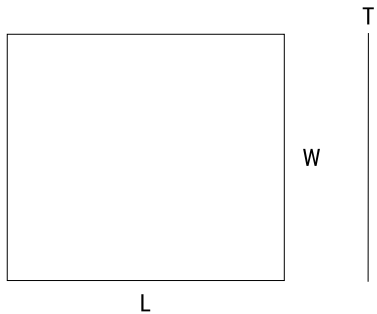

General Information	
Series:	EFX6
Style:	Sheet
Description:	Flex Suppressor High Permeability Type
Features:	High Permeability Type
RoHS:	Yes
Qualifications:	UL94 HB, UL File No. E176124
Environment:	RoHS Compliant, Halogen Free, PVC Free, Lead Free, Red Phosphorus Free

Dimensions	
Sheet Size	80x80mm
L	80mm NOM
W	80mm NOM
T	0.1mm NOM

Specifications	
Temperature Range:	-40/+105°C
Magnetic Permeability:	160 μ At 3MHz
Effective Frequency:	10 GHz MAX
Resistance:	1 MOhms MIN
Specific Gravity:	3.8 Atm TYP

Packaging Specifications	
Weight:	2.53 g