




mecalelectro

Safety holding electromagnet – P 5.18.44

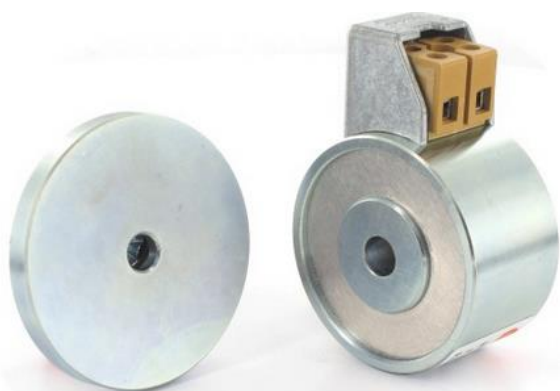

Diameter: 48 mm

Holding force when power on: 50 daN

Power Consumption: 1.6 W

Total mass: 300 g

Degree of protection / Energetic class: IP 40 / B

Standard supplies: 24 - 48Vcc

Possible supplies: From 12 to 196Vcc

Duty Cycle: Permanent (100%)

Standard: NF S 61-937

Examples of applications: Maintenance of fire dampers or smoke evacuation traps, blocking of parts, positioning, control of ventilation flaps.