


# Magna-Cut Reamers

Magna-Cut Reibahlen

Alésoirs Magna-Cut

**HSS**

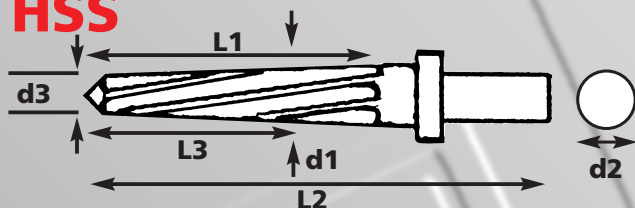

**RANGE 3/8" to 1"**

**10mm to 26mm**

**LIST CODE M097**

**LEFT HAND SPIRAL**

**RIGHT HAND CUTTING**

**TAPER 1 in 10**

**TOLERANCES +0.1mm**

**-0**

| Code       | d1           |    | d3    |       | L1      |     | L2      |     | L3    |     | d2   | No. of Flutes |
|------------|--------------|----|-------|-------|---------|-----|---------|-----|-------|-----|------|---------------|
|            | Inch         | mm | inch  | mm    | inch    | mm  | inch    | mm  | inch  | mm  | inch |               |
| M09700375F | 3/8          |    | 0.193 |       | 3       |     | 5       |     | 2     |     | 3/8  | 4             |
| M09700393M |              | 10 |       | 5.2   |         | 76  |         | 127 |       | 55  | 3/8  | 4             |
| M09700472M |              | 12 |       | 5.6   |         | 102 |         | 152 |       | 71  | 1/2  | 5             |
| M09700500F | 1/2          |    | 0.236 |       | 3-15/16 |     | 5-15/16 |     | 2-5/8 |     | 1/2  | 5             |
| M09700551M |              | 14 |       | 7.8   |         | 102 |         | 152 |       | 71  | 1/2  | 5             |
| M09700625F | 5/8          |    | 0.264 |       | 4-1/2   |     | 6-9/16  |     | 3-3/8 |     | 1/2  | 5             |
| M09700708M |              | 18 |       | 9.2   |         | 125 |         | 178 |       | 97  | 1/2  | 5             |
| M09700750F | 3/4          |    | 0.458 |       | 4-15/16 |     | 7       |     | 3-3/4 |     | 1/2  | 5             |
| M09700866M |              | 22 |       | 13.00 |         | 132 |         | 184 |       | 103 | 1/2  | 5             |
| M09700875F | 7/8          |    | 0.585 |       | 5-3/16  |     | 7-1/4   |     | 3-7/8 |     | 1/2  | 5             |
| M09701000F | 1            |    | 0.713 |       | 5-3/16  |     | 7-1/4   |     | 3-7/8 |     | 1/2  | 5             |
| M09701023M |              | 26 |       | 17.20 |         | 132 |         | 184 |       | 103 | 1/2  | 5             |
| M09700FSET | 3/8" to 1"   |    |       |       |         |     |         |     |       |     |      |               |
| M09700MSET | 10mm to 26mm |    |       |       |         |     |         |     |       |     |      |               |