




Fibre optic through-beam sensor

FE-30-P-A-R6

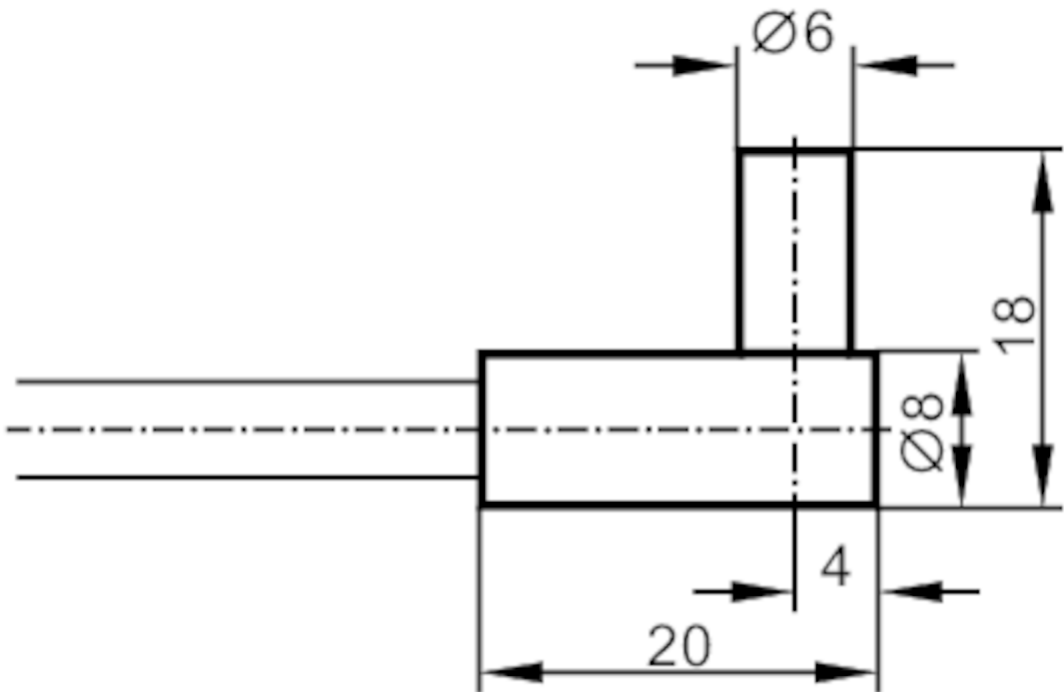

Application		
Function principle	Through-beam sensor	
Application	For use in industrial environments	
Detection zone		
Range with fibre-optic amplifier type	OIF	
OIF		
Range of fibre optics	[mm]	300
Operating conditions		
Ambient temperature	[°C]	-20...80
Mechanical data		
Weight	[g]	107.5
Version of sensing head	angled	
Sensing head diameter	[mm]	6
Total length	[mm]	600
Min. bending radius	[mm]	30
Fibre arrangement		
Materials	Adapter: PA	
Fibre material	glass	
Fibre head material	aluminium	

E20165



Fibre optic through-beam sensor

FE-30-P-A-R6

Fibre sheath material	PVC
Accessories	
Items supplied	Mounting clamp:, E10221
Remarks	
Pack quantity	1 pcs.