


Data sheet

AC/AC linear adaptors

UK 14VA

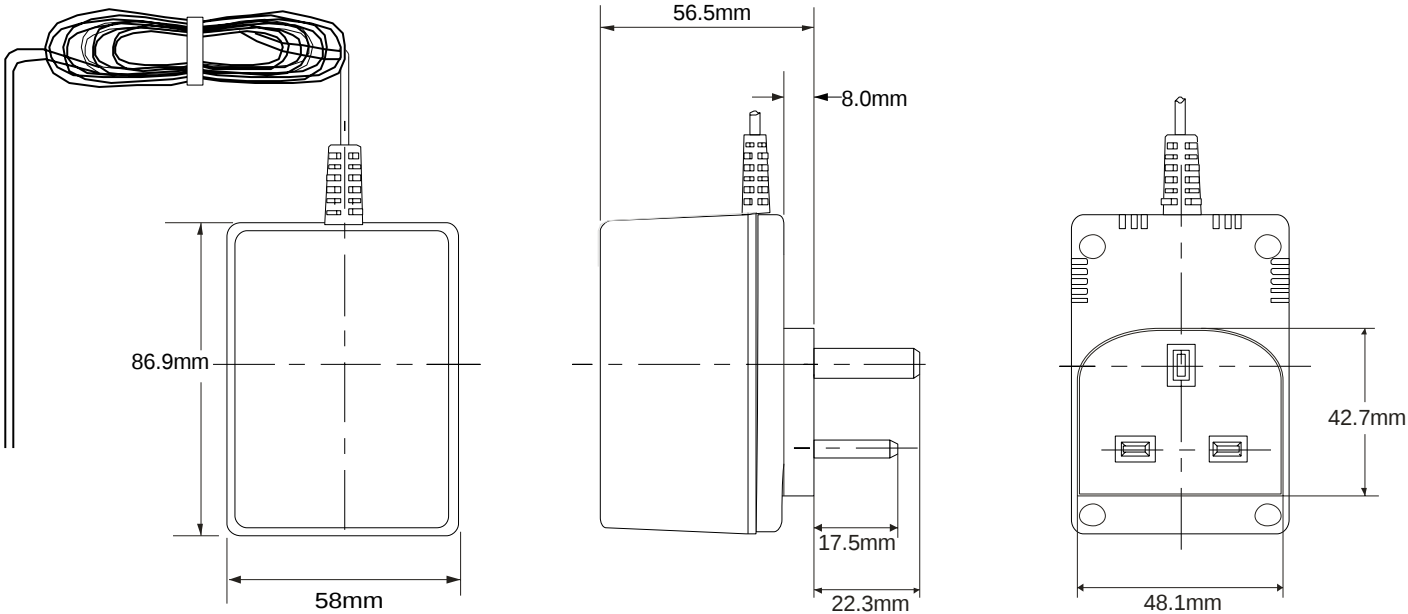

Specification:

Input: 230V, 50Hz
Maximum no load primary current: 60mA

Hi-pot, primary to secondary: 3.3kV rms for 3 seconds
Insulation breakdown, primary to secondary @ 500VDC: 7M ohms
Primary circuit protected by 125°C, 1A single shot thermal fuse
PSU housing colour: BLACK
Cable length: 1800mm +/-150mm
Cable colour: BLACK

Tolerance on dimensions: +/- 0.5mm unless stated otherwise

Part number	Open circuit voltage (VAC)	Full load voltage (VAC)	Current (mA)
AD4824-09-1500UK	11.7	9	1500
AD4824-12-1200UK	15.5	12	1200
AD4824-18-0770UK	22.5	18	770
AD4824-24-0580UK	29.9	24	580

